


Panhead Screw, Torx with Grounding

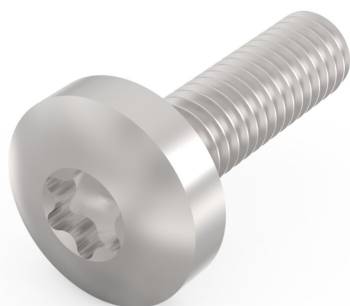

Good compromise between profile height and bearing area. Better load distribution than round heads.
Compatible with automated assembly.

FEATURES

For fixing Horizonrail rails or chassis plate and covers onto Side panel, with GND/ Earthing function

Torx imprint bears greater torque

The star-shaped head prevents cam-out

Product Family:	EuropacPRO
Type:	Panhead Screw
Product Type:	Screw
Material:	Steel
Finish:	Zinc Plated



SPECIFICATIONS

Catalog Number	Length	Package Quantity	Thread Size	Works With	Torque
24560-151	6mm	100	M4	Subracks	1.3N·m
24560-155	10mm	100	M4	Subracks	2.4N·m
24560-131	14mm	10	M4	Subracks	2.4N·m
24560-130	14mm	100	M4	Subracks	2.4N·m

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE