


# 19" Front Panel for Thermostat With Digital Display, 1 U

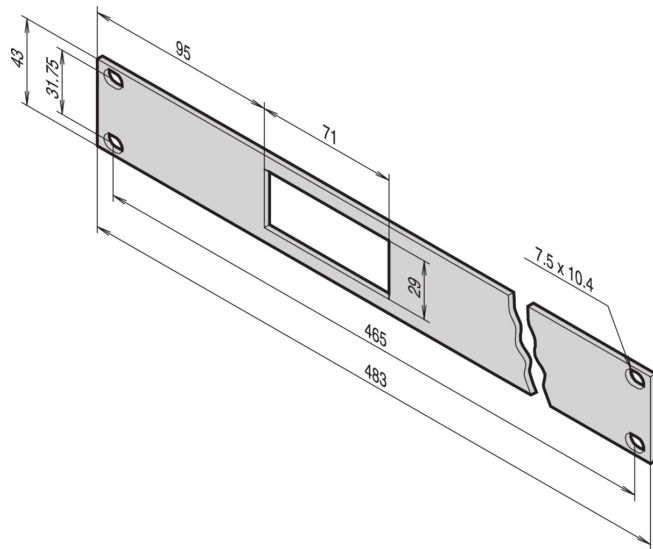

19" Front Panel for Thermostat With Digital Display, 1 U

## FEATURES

19" Front Panel, 1 U, with cut-out for thermostat with digital display

Accessory Type: Front panel



## SPECIFICATIONS

Table 1/3

| Catalog Number | Type            | Mounting       | EMC Shielding | Material | Front Finish | Rear Finish |
|----------------|-----------------|----------------|---------------|----------|--------------|-------------|
| 30118-315      | 19" Front Panel | Screw-on Front | No            | Aluminum | Painted      | Painted     |
| 30118-267      | 19" Front Panel | Screw-on Front | No            | Aluminum | Anodized     | Anodized    |
| 30118-360      | 19" Front Panel | Screw-on Front | No            | Aluminum | Painted      | Painted     |

Table 2/3

| Catalog Number | Color Code | Rack Height | Height | Rack Width | Width | Depth |
|----------------|------------|-------------|--------|------------|-------|-------|
| 30118-315      | RAL 7035   | 1U          | 43mm   | 95HP       | 483mm | 3mm   |
| 30118-267      |            | 1U          | 35mm   |            | 76mm  | 3mm   |
| 30118-360      | RAL 7021   | 1U          | 43mm   | 95HP       | 483mm | 3mm   |

Table 3/3

| Catalog Number | Package Quantity | Finish        |
|----------------|------------------|---------------|
| 30118-315      | 1                | Powder Coated |

| Catalog Number | Package Quantity | Finish        |
|----------------|------------------|---------------|
| 30118-267      | 1                | Anodized      |
| 30118-360      | 1                | Powder Coated |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE