

Power Socket With Integrated Fuse, LPS


Easy to mount power sockets, to be mounted on a DIN rail, for use when external equipment needs to be plugged in.

INDUSTRY STANDARDS

cULus_UL listed

CE

GOST

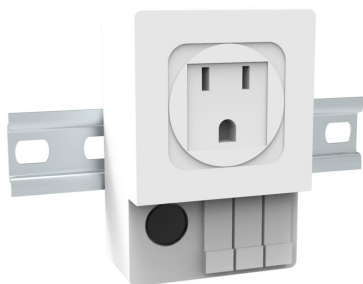

FEATURES

Description: DIN rail mounted electrical socket. Pressure clamp connection for easy and quick wiring.

Dimensions: 92 mm x 62 mm x 48 mm.

Connection: 3 pressure clamps for stranded and rigid wire 0.5-2.5 mm². Integrated fuse 6,3A 5x20 mm.

Finish: Light grey.

Material: Plastic UL 94 V-0.

Pack quantity: 1 piece.

Color: Light Gray
Material: Plastic
Color Code: RAL 7035
Finish: Smooth

SPECIFICATIONS

Catalog Number	Height	Width	Depth	Socket Type	Weight
LPS10FR	92mm	62mm	48mm	Type F	120kg
LPS10	92mm	62mm	48mm	SCHUKO	120kg
LPS10USA	92mm	62mm	48mm	Type A	120kg
LPS10UK	92mm	62mm	48mm	Type G	120kg

Catalog Number	Height	Width	Depth	Socket Type	Weight
LPS10CH	92mm	62mm	48mm	Switzerland	120kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE