


# Front Panel EMC Stainless Steel Shielding Kit

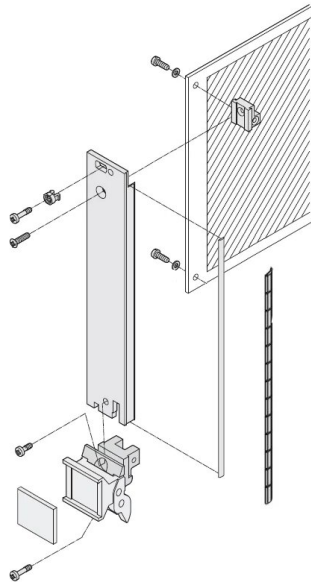

The stainless steel EMC gaskets are inserted into the lateral slots of the shieldable front panels (2 pieces per front panel).

## FEATURES

The stainless steel EMC gaskets are inserted into the lateral slots of the shieldable front panels (2 pieces per front panel)

EMC contact strip, stainless steel

Temperature range -200 °C ... +160 °C

|                        |                                                                              |
|------------------------|------------------------------------------------------------------------------|
| <b>Works With:</b>     | Sub racks; Cases; Front Panels                                               |
| <b>Product Family:</b> | EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Frame Type Plug-In Unit |
| <b>Product Type:</b>   | Shielding Kit                                                                |
| <b>Material:</b>       | Stainless Steel                                                              |



## SPECIFICATIONS

| Catalog Number | Rack Height | Package Quantity | Depth (D) | Height (H) | Width (W) |
|----------------|-------------|------------------|-----------|------------|-----------|
| 21101-775      | 2U          | 10               | 2.22mm    | 52mm       | 4.97mm    |
| 21101-776      | 2U          | 100              |           |            |           |
| 21101-713      | 4U          | 10               | 2.22mm    | 142mm      | 4.97mm    |
| 21101-707      | 6U          | 10               | 2.22mm    |            | 4.97mm    |
| 21101-709      | 9U          | 10               | 2.22mm    |            | 4.97mm    |
| 21101-706      | 3U          | 100              | 2.22mm    | 97mm       | 4.97mm    |
| 21101-705      | 3U          | 10               | 2.22mm    | 97mm       | 4.97mm    |
| 21101-714      | 4U          | 100              |           |            |           |
| 21101-777      | 5U          | 10               |           |            |           |
| 21101-778      | 5U          | 100              |           |            |           |
| 21101-708      | 6U          | 100              |           |            |           |
| 21101-710      | 9U          | 100              |           |            |           |


## ADDITIONAL PRODUCT DETAILS

---

Please order assembly tool separately.

## DIAGRAMS

---

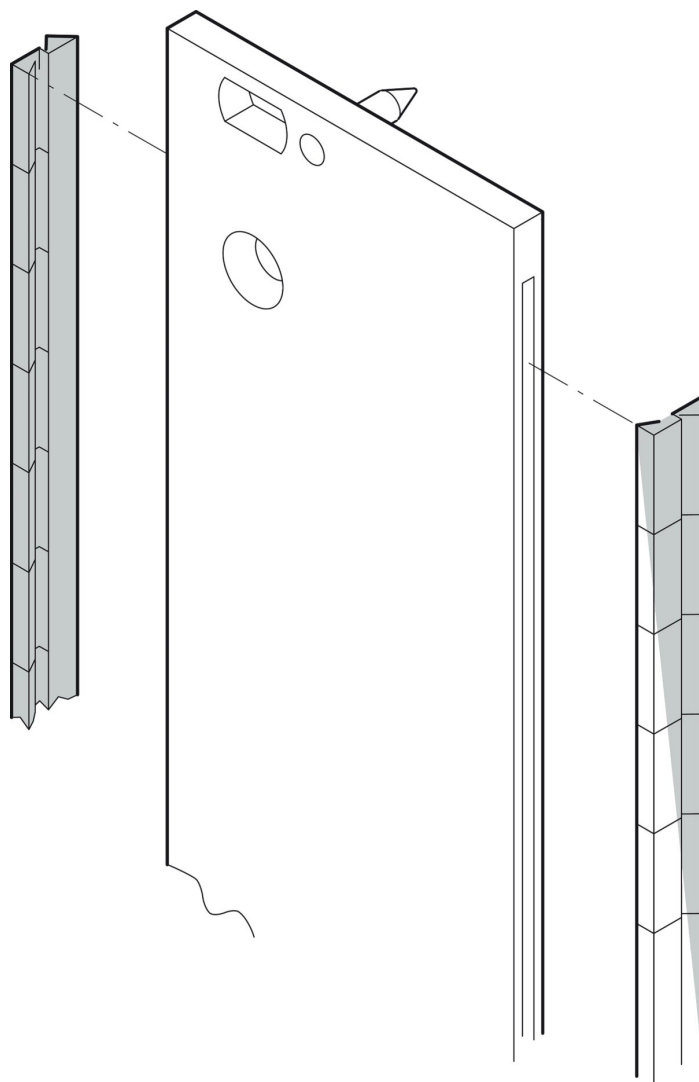

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**