

nVent CADDY Macrofix Plus NI EZ with Easy Closure



FEATURES

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

Finish: Electrogalvanized
Material: Steel



SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Width (W)	Thickness (T)
MPZ040	595056	32	40.0 - 42.4 mm	M10	30 mm	1.5 mm
MPZ025	595053	20	25.0 - 26.9 mm	M10	30 mm	1.5 mm
MPZ020	595052	15	20.0 - 21.3 mm	M10	30 mm	1.5 mm
MPZ032	595054	25	32.0 - 33.7 mm	M10	30 mm	1.5 mm
MPZ050	595057	40	48.3 - 50 mm	M10	30 mm	2 mm
MPZ063	595059	50	60.3 - 63 mm	M10	30 mm	2 mm
MPZ075	595061	65	75.0 - 76.1 mm	M10	30 mm	2 mm
MPZ110	595063	100	110.0 - 114.3 mm	M10	30 mm	2.5 mm

Table 2/2

Catalog Number	Article Number	Static Load	Certifications
MPZ040	595056	1125N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ025	595053	1125N	AON Fire Protection, BB019, pipe hangers, FM Approved, Pipe Hanger Components
MPZ020	595052	1125N	AON Fire Protection, BB019, pipe hangers
MPZ032	595054	1125N	FM Approved, Pipe Hanger Components, AON Fire Protection, Macrofix Plus NI EZ
MPZ050	595057	1725N	FM Approved, Pipe Hanger Components, AON Fire Protection, Macrofix Plus NI EZ
MPZ063	595059	1725N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ075	595061	1725N	
MPZ110	595063	2000N	

DIAGRAMS

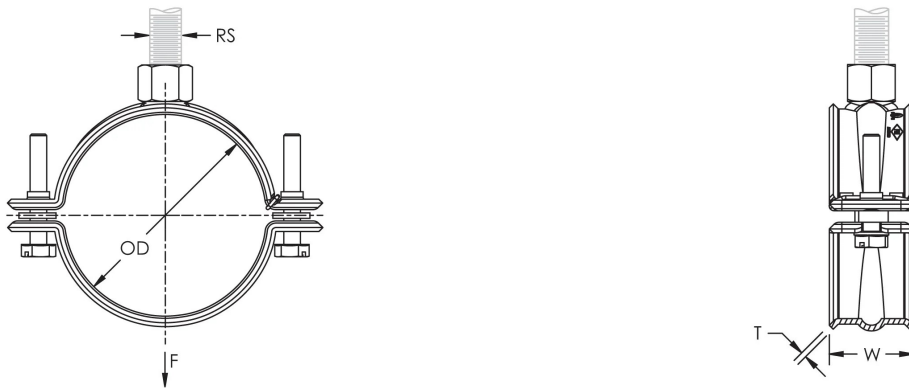

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

