

# Multi-Purpose Grounding Clamp, Stainless Steel



## FEATURES

Convenient multi-purpose clamp designed to accommodate round conductors, flat conductors, ground rods and rebar

Stainless steel material with inner plate allows compatibility between most dissimilar metals

## SPECIFICATIONS

Table 1/3


| Catalog Number | Article Number | Material                        | Conductor Size                                                                     | Tape Size     | Ground Rod Diameter, Nominal | Ground Rod Diameter, Actual (Ø) |
|----------------|----------------|---------------------------------|------------------------------------------------------------------------------------|---------------|------------------------------|---------------------------------|
| MPSC404SS      | 120319         | Stainless Steel 304 (EN 1.4301) | 35 mm <sup>2</sup> Stranded - 50 mm <sup>2</sup> Stranded, #2 Stranded - 1/0 Solid | 40 x 4 mm Max | 5/8" - 3/4"                  | 14.2 - 19 mm                    |

Table 2/3

| Catalog Number | Article Number | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Length (L) | Width (W) |
|----------------|----------------|--------------------|----------------|--------------------|------------|-----------|
| MPSC404SS      | 120319         | 16 - 20 mm         | #5 - #6        | 15M - 20M          | 65mm       | 65 mm     |

Table 3/3

| Catalog Number | Article Number | Torque (TQ) | Complies With   |
|----------------|----------------|-------------|-----------------|
| MPSC404SS      | 120319         | 23 N·m      | IEC® EN 62561-1 |

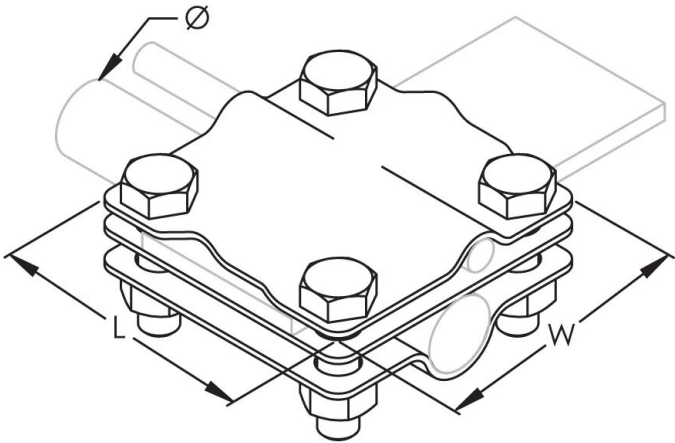

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE