


# Straight Coupler

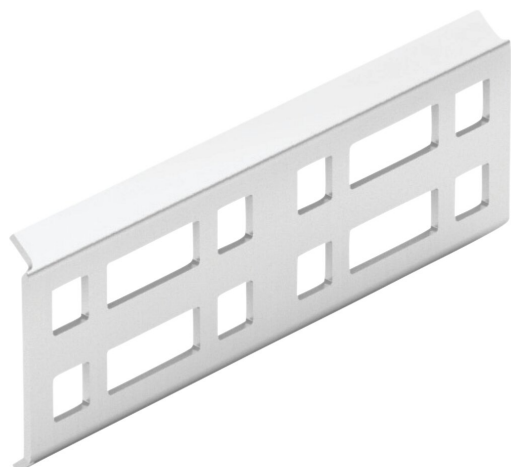

## FEATURES

Provides high-strength joint with SPEEDWAY Cable Ladder profile

Installs quickly and easily with included hardware


Multiple slots allow for field adjustments



## SPECIFICATIONS

| Catalog Number | Article Number | Material | Finish             | A      | B     | C      |
|----------------|----------------|----------|--------------------|--------|-------|--------|
| CLSW4CSGA      | 842010         | Steel    | Hot-Dip Galvanized | 160 mm | 62 mm | 2.5 mm |

## DIAGRAMS

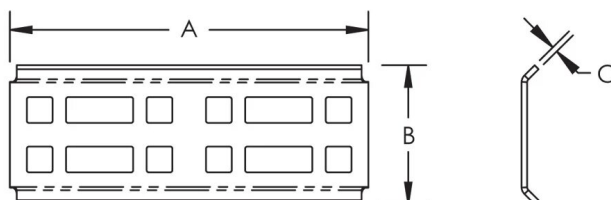

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

