


# EuropacPRO 19" Subrack Kit for Backplane, Light, Unshielded

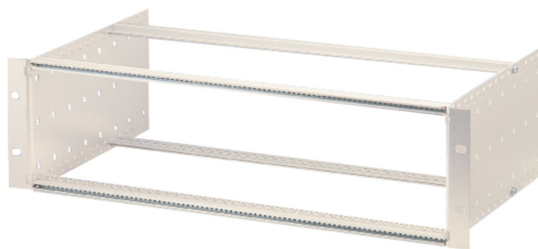

Non-EMC shielded subrack for backplane mounting, light version.

## FEATURES

Subrack with side panel type L ("light") with integrated 19" support brackets

Horizontal rail type "light"

Aluminum construction

Rear horizontal rails for backplane mounting with insulation strip

Installed load up to 7.5 kg

Supplied as space-saving flat-pack

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Modifications such as cutouts, different finishes or dimensions available

|                       |                      |
|-----------------------|----------------------|
| <b>Material:</b>      | Aluminum             |
| <b>Finish:</b>        | Anodized; Passivated |
| <b>EMC Shielding:</b> | No                   |
| <b>Product Type:</b>  | Subrack/Chassis      |



## SPECIFICATIONS

Table 1/2

| Catalog Number | Rack Height | Depth | Package Quantity | For Mounting | Board Depth         | Handle Included |
|----------------|-------------|-------|------------------|--------------|---------------------|-----------------|
| 24564-131      | 3U          | 175mm | 1                | Backplane    | 160mm               | No              |
| 24564-132      | 3U          | 235mm | 1                | Backplane    | 160mm, 220mm        | No              |
| 24564-433      | 6U          | 295mm | 1                | Backplane    | 160mm, 220mm, 280mm | No              |
| 24564-133      | 3U          | 295mm | 1                | Backplane    | 160mm, 220mm, 280mm | No              |
| 24564-432      | 6U          | 235mm | 1                | Backplane    | 160mm, 220mm        | No              |
| 24564-431      | 6U          | 175mm | 1                | Backplane    | 160mm               | No              |

Table 2/2

| Catalog Number | Mounting | Complies With                                 | Rack Width | Static Load |
|----------------|----------|-----------------------------------------------|------------|-------------|
| 24564-131      | Rack     | IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1 | 84HP       | 7.5kg       |
| 24564-132      | Rack     | IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1 | 84HP       | 7.5kg       |
| 24564-433      | Rack     | IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1 | 84HP       | 7.5kg       |
| 24564-133      | Rack     | IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1 | 84HP       | 7.5kg       |
| 24564-432      | Rack     | IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1 | 84HP       | 7.5kg       |
| 24564-431      | Rack     | IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1 | 84HP       | 7.5kg       |

## ADDITIONAL PRODUCT DETAILS

Subrack is not prepared for shielding, retrofit for protection class IP 20 possible

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**