

Branch Line Restraint Pipe Attachment



FEATURES

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe



Shear-off head helps ensure correct torque and simplifies inspection

Finish: Electrogalvanized
Material: Steel



SPECIFICATIONS

Catalog Number	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Length (L)	Width (W)
CSBBRP0200EG	404480	50	60.3 mm	10, 12	100.3 mm	68.3mm	22.2 mm
CSBBRP0125EG	404478	32	42.2 mm	10, 12	82.6 mm	50mm	22.2 mm
CSBBRP0100EG	404477	25	33.4 mm	10, 12	73.7 mm	41.4mm	22.2 mm
CSBBRP0150EG	404479	40	48.3 mm	10, 12	88.9 mm	56.1mm	22.2 mm

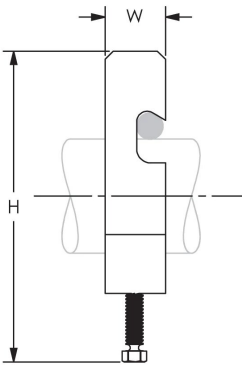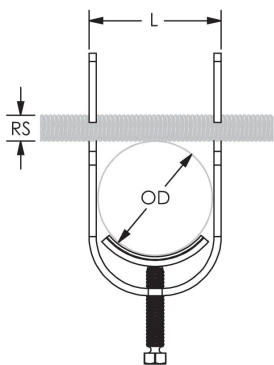

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

