


# RatiopacPRO EMC Front Panel, Slotted, Shielded

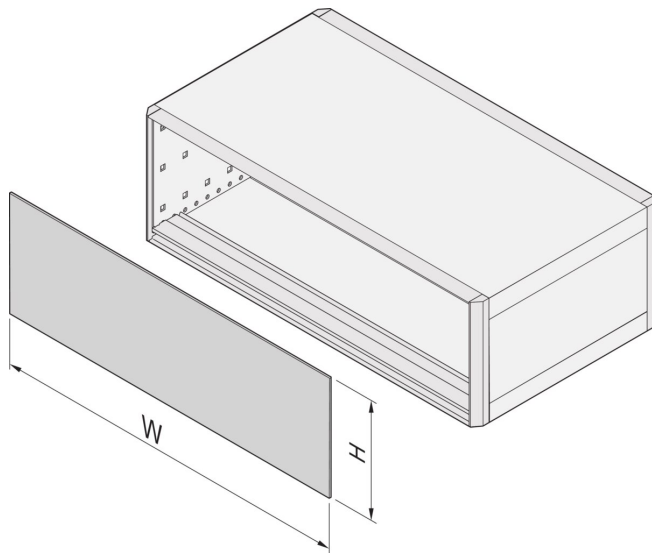

The EMC front panel can be inserted in special horizontal rails with an elevation. No screws are needed for the fixing. The design enable a users to use a front foil.

## FEATURES

Fixing does not require screws

Special horizontal rails cover the edges of the front panel (top and bottom) and prevent bowing of the front panel

**Material:** Aluminum  
**Finish:** Anodized; Passivated  
**Accessory Type:** Front panel  
**Product Type:** Front Panel



## SPECIFICATIONS

Table 1/2

| Catalog Number | Rack Height | Rack Width | Package Quantity | Front Finish | Rear Finish | Treated Edges |
|----------------|-------------|------------|------------------|--------------|-------------|---------------|
| 24572-609      | 4U          | 63HP       | 1                | Anodized     | Conductive  | No            |
| 24572-610      | 4U          | 84HP       | 1                | Anodized     | Conductive  | No            |
| 24572-604      | 3U          | 42HP       | 1                | Anodized     | Conductive  | No            |
| 24572-599      | 2U          | 28HP       | 1                | Anodized     | Conductive  | No            |
| 24572-607      | 4U          | 28HP       | 1                | Anodized     | Conductive  | No            |
| 24572-600      | 2U          | 42HP       | 1                | Anodized     | Conductive  | No            |
| 24572-601      | 2U          | 63HP       | 1                | Anodized     | Conductive  | No            |
| 24572-605      | 3U          | 63HP       | 1                | Anodized     | Conductive  | No            |
| 24572-602      | 2U          | 84HP       | 1                | Anodized     | Conductive  | No            |
| 24572-603      | 3U          | 28HP       | 1                | Anodized     | Conductive  | No            |
| 24572-608      | 4U          | 42HP       | 1                | Anodized     | Conductive  | No            |

| Catalog Number | Rack Height | Rack Width | Package Quantity | Front Finish | Rear Finish | Treated Edges |
|----------------|-------------|------------|------------------|--------------|-------------|---------------|
| 24572-606      | 3U          | 84HP       | 1                | Anodized     | Conductive  | No            |

Table 2/2

| Catalog Number | Depth | Height  | Width   |
|----------------|-------|---------|---------|
| 24572-609      | 2.5mm | 172.9mm | 319.7mm |
| 24572-610      | 2.5mm | 172.9mm | 426.4mm |
| 24572-604      | 2.5mm | 128.4mm | 213.2mm |
| 24572-599      | 2.5mm | 84mm    | 141.9mm |
| 24572-607      | 2.5mm | 172.9mm | 141.9mm |
| 24572-600      | 2.5mm | 84mm    | 213.2mm |
| 24572-601      | 2.5mm | 84mm    | 319.7mm |
| 24572-605      | 2.5mm | 128.4mm | 319.7mm |
| 24572-602      | 2.5mm | 84mm    | 426.4mm |
| 24572-603      | 2.5mm | 128.4mm | 141.9mm |
| 24572-608      | 2.5mm | 172.9mm | 213.2mm |
| 24572-606      | 2.5mm | 128.4mm | 426.4mm |

## ADDITIONAL PRODUCT DETAILS

To obtain a shielded case, all EMC sealings must be fitted (front panel/rear panel - side panel; side panel - cover plate; front panel/rear panel - horizontal rail; horizontal rail - horizontal rail).

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**