

Branch Line Restraint Structure Attachment to Threaded Hole



FEATURES

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to concrete anchors or structural attachments with female threads

Can be used for bolting through steel

Finish: Electrogalvanized
Material: Steel



SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Rod Size (RS)	Height (H)	Length (L)	Width (W)	Screw Diameter (Sc)
CSBBRS3EG		0.375, 0.5	28.2 mm	40.4mm	26.9 mm	0.375
CSBBRS3MEG	402241	10, 12	28.2 mm	40.4mm	26.9 mm	10

Table 2/2

Catalog Number	Article Number	Screw Length (L)	Certifications
CSBBRS3EG		19mm	OSHDP, UL, FM Approved, Seismic
CSBBRS3MEG	402241	19mm	UL, FM Approved, Seismic, AON Fire Protection, Rigid Seismic

ADDITIONAL PRODUCT DETAILS

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

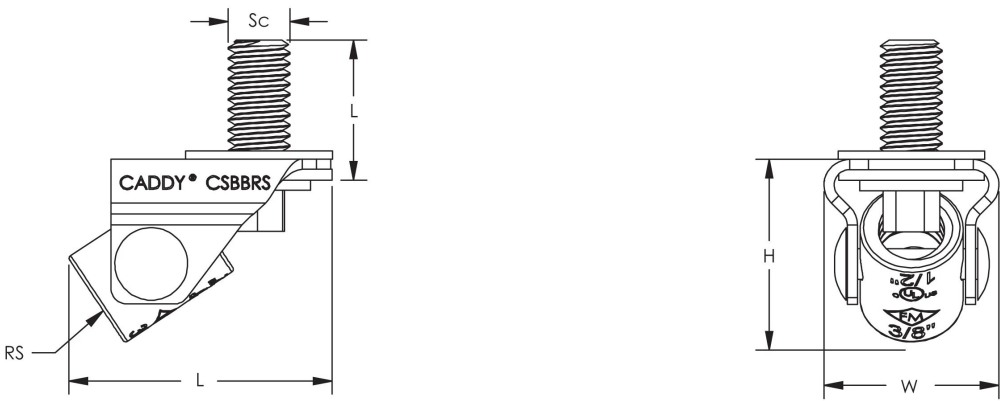

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

