

PDR Perforated Symmetric Profile



FEATURES

Rapid assembly of all kinds of frameworks

High mechanical resistance

High corrosion resistance

RoHS compliant

Conforms to EN 60715 and 50022 and DIN 46277

Finish: Electrogalvanized

Material: Steel



SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Height (H)	Width (W)	Length (L)	Thickness (T)	A
PDR7-3M	557860	35 mm	7.5 mm	3000mm	1 mm	4 mm
PDR5-2M	557750	15 mm	5.5 mm	2000mm	1 mm	2.25 mm
PDR7-2M	557850	35 mm	7.5 mm	2000mm	1 mm	4 mm
PDR7-2M-5-2	557855	35 mm	7.5 mm	2000mm	1 mm	4 mm
PDR15-3M	557960	35 mm	15 mm	3000mm	1.5 mm	4 mm
PDR15-2M	557950	35 mm	15 mm	2000mm	1.5 mm	4 mm

Table 2/2

Catalog Number	Article Number	B	C	D	Unit Weight
PDR7-3M	557860	7 mm	18 mm	6.2 mm	0.92 kg
PDR5-2M	557750	7.8 mm	12.2 mm	4.2 mm	0.28 kg
PDR7-2M	557850	7 mm	18 mm	6.2 mm	0.62 kg
PDR7-2M-5-2	557855	11 mm	25 mm	5.2 mm	0.62 kg

Catalog Number	Article Number	B	C	D	Unit Weight
PDR15-3M	557960	7 mm	18 mm	6.2 mm	1.81 kg
PDR15-2M	557950	7 mm	18 mm	6.2 mm	1.2 kg

DIAGRAMS

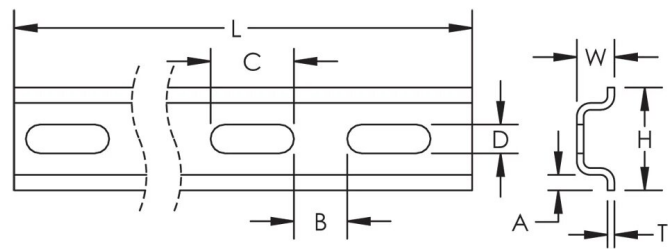

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE