

nVent CADDY Cat HP J-Hook Tree, Ceiling Mount



FEATURES

Ideal for attaching to concrete, steel or wood surfaces

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Ready to use out of the box, saving installation time and labor

Requires no screws, rivets or special tools for assembly

Single- or double-sided tree configurations provide multiple J-Hooks with one structural attachment

Provides superior fill capacity and load rating over most other non-continuous cable support alternatives

Complies with EN 50174-2

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

Finish: Pregalvanized

Material: Steel

SPECIFICATIONS

Table 1/2

Catalog Number	Type	Diameter (Ø)	Tiers	Height (H)	Width (W)	Hole Size 1 (HS1)
CAT32HPDCM3 	Double Sided	2"	3	15 1/4"	5 13/16"	0.41"

Catalog Number	Type	Diameter (Ø)	Tiers	Height (H)	Width (W)	Hole Size 1 (HS1)
CAT64HPSCM2 	Single Sided	4"	2	15 1/4"	5 7/16"	0.41"
CAT32HPDCM4 	Double Sided	2"	4	20 1/4"	5 13/16"	0.41"
CAT64HPDCM4	Double Sided	4"	4	30 1/4"	10"	0.41"
CAT64HPDCM3 	Double Sided	4"	3	22 3/4"	10"	0.41"
CAT32HPSCM2 	Single Sided	2"	2	10 1/4"	3 5/16"	0.41"
CAT64HPSCM4 	Single Sided	4"	4	30 1/4"	5 7/16"	0.41"
CAT32HPDCM2 	Double Sided	2"	2	10 1/4"	5 13/16"	0.41"
CAT32HPSCM3 	Single Sided	2"	3	15 1/4"	3 5/16"	0.41"
CAT32HPSCM4 	Single Sided	2"	4	20 1/4"	3 5/16"	0.41"
CAT64HPDCM2 	Double Sided	4"	2	15 1/4"	10"	0.41"
CAT64HPSCM3 	Single Sided	4"	3	22 3/4"	5 7/16"	0.41"

Table 2/2


Catalog Number	Hole Size 2 (HS2)	A	B	Static Load 1 (F1)	Static Load 2 (F2)
CAT32HPDCM3 	0.18"	1 7/16"	2"	360lb	180lb
CAT64HPSCM2 	0.18"	1 7/16"	2"	120lb	120lb
CAT32HPDCM4 	0.18"	1 7/16"	2"	480lb	180lb
CAT64HPDCM4	0.18"	1 7/16"	2"	480lb	180lb
CAT64HPDCM3 	0.18"	1 7/16"	2"	360lb	180lb
CAT32HPSCM2 	0.18"	1 7/16"	2"	120lb	120lb
CAT64HPSCM4 	0.18"	1 7/16"	2"	240lb	180lb
CAT32HPDCM2 	0.18"	1 7/16"	2"	240lb	180lb
CAT32HPSCM3 	0.18"	1 7/16"	2"	180lb	180lb
CAT32HPSCM4 	0.18"	1 7/16"	2"	240lb	180lb
CAT64HPDCM2 	0.18"	1 7/16"	2"	240lb	180lb
CAT64HPSCM3 	0.18"	1 7/16"	2"	180lb	180lb

ADDITIONAL PRODUCT DETAILS

Static loads represent maximum load limit of J-Hook tree. Static load limit of each J-Hook is 60 lb (270 N).

Refer to Static Load 1 when fastening J-Hook tree using Hole Size 1. Refer to Static Load 2 when fastening J-Hook tree using Hole Size 2.

Non-continuous supports may not exceed spacing of 5' (1.5 m) per TIA 569-C.9.7 and EN 50174-2.

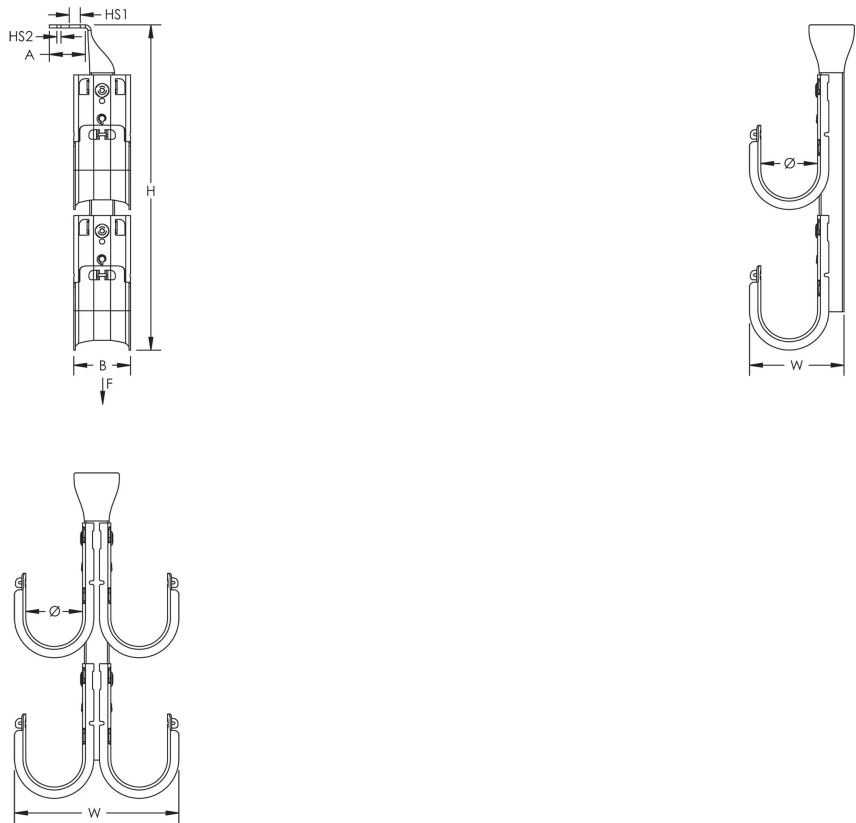

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

