

nVent CADDY Macrofix Plus NI EZ with Easy Closure



FEATURES

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

Finish: Electrogalvanized
Material: Steel




SPECIFICATIONS

Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	Width (W)	Thickness (T)	Static Load (F)	Certifications
4290075EG	3/4"	0.980" - 1.06"	3/8"	1 3/16"	1/16"	250lbf	FM Approved, Pipe Hanger Components, UL, cUL
4290125EG	1 1/4" Min	1.570" - 1.67"	3/8"	1 3/16"	1/16"	250lbf	cUL, FM Approved, Pipe Hanger Components, UL
4290100EG	1"	1.260" - 1.33"	3/8"	1 3/16"	1/16"	250lbf	cUL, UL, FM Approved, Pipe Hanger Components
4290050EG	1/2"	0.790" - 0.84"	3/8"	1 3/16"	1/16"	250lbf	UL, cUL
4290200EG	2" Min	2.370" - 2.48"	3/8"	1 3/16"	5/64"	320lbf	FM Approved, Pipe Hanger Components, UL, cUL

Catalog Number	Pipe Size	Outer Diameter(OD)	Rod Size (RS)	Width (W)	Thickness (T)	StaticLoad (F)	Certifications
4290150EG	1 1/2"	1.900" - 1.97"	3/8"	1 3/16"	5/64"	320lbf	cUL, FM Approved, Pipe Hanger Components, UL
4290250EG	2 1/2"	2.88" - 3"	3/8"	1 3/16"	5/64"	320lbf	cUL, UL

DIAGRAMS

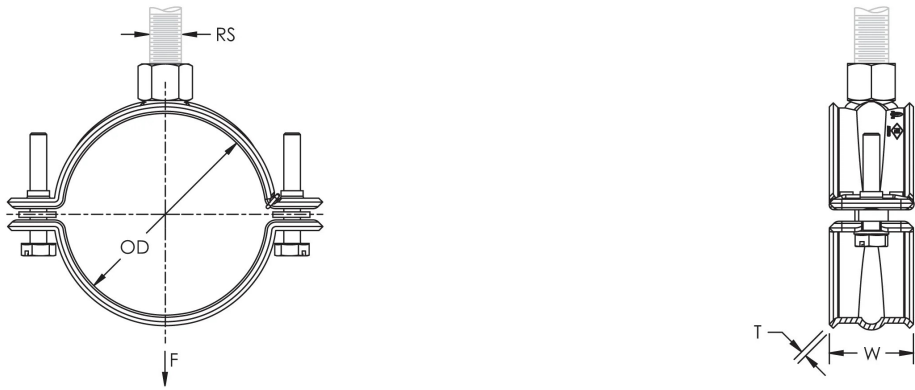

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

