

nVent CADDY Pyramid ST Fixed Strut Support



The nVent CADDY Pyramid ST Fixed Strut Support offers a simple and adaptable solution for mounting electrical and mechanical services on commercial rooftops. This support system is engineered to evenly distribute weight across the base, ensuring optimal load management. Additionally, the foam pad on the underside provides a low-abrasion interface that protects roof membranes, eliminating the need for a slip sheet.

Constructed with UV-stabilized base materials and hot-dip galvanized strut profiles, these supports deliver exceptional corrosion resistance. The standard strut profile attachment point accommodates a wide range of components, including conduit, pipe, and strut fasteners, allowing for secure and efficient installation.

FEATURES

Effective load distribution across uneven surfaces

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Ready to use out-of-the-box, saving installation time and improving productivity

Available in multiple sizes and load ratings for tailored applications

Lightweight and easy to transport

Hot-dip galvanized and UV stabilized for long-lasting performance

Static Load Safety Factor: 3:1
Finish: Hot-Dip Galvanized
Material: Polyethylene;Polypropylene;Steel



SPECIFICATIONS

Table 1/2

Catalog Number	Temperature	Length 1 (L1)	Length 2 (L2)	Height (H)	Width (W)	Surface Area
PSF6C	-50 to 150 °F	6"	8"	4.8"	6"	41in ²
PSF10C	-50 to 150 °F	10"	12 1/2"	4.8"	8"	92in ²
PSF10A	-50 - 150	10	12.5	5.6	8	92
PSF10D	-50 to 150 °F	10"	12 1/2"	6.4"	8"	92in ²


Catalog Number	Temperature	Length 1 (L1)	Length 2 (L2)	Height (H)	Width (W)	Surface Area
PSF16C	-50 to 150 °F	16"	19"	4.8"	8"	142in ²
PSF16A	-50 - 150	16	19	5.6	8	142
PSF16D	-50 to 150 °F	16"	19"	6.4"	8"	142in ²

Table 2/2			
Catalog Number	Unit Weight	Static Load (F)	Certifications
PSF6C	1 lb	300lb	
PSF10C	2 lb	1000lb	ITB
PSF10A	2.5	1000lb	
PSF10D	3 lb	1000lb	ITB
PSF16C	3 lb	1500lb	ITB
PSF16A	4	1500lb	
PSF16D	5 lb	1500lb	ITB

ADDITIONAL PRODUCT DETAILS

Static load at 73.1 kPa (10.6 psi) roof loading. Contact project or roofing engineer for maximum allowable load on individual project roof system.

DIAGRAMS

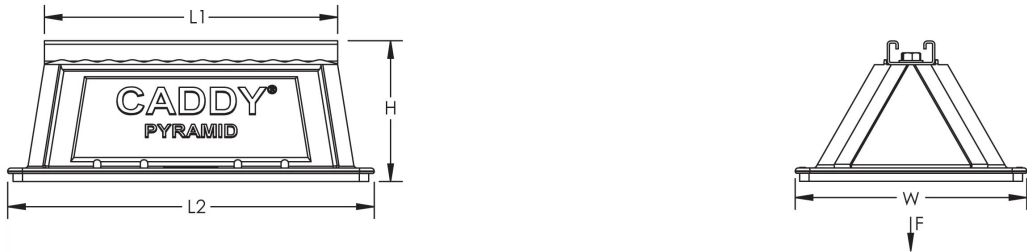

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

