

DR Symmetric Profile



FEATURES

Rapid assembly of all kinds of frameworks

High mechanical resistance

High corrosion resistance

Conforms to EN 60715 and 50022 and DIN 46277

RoHS compliant

Finish: Electrogalvanized


Material: Steel



SPECIFICATIONS

Catalog Number	Article Number	Height (H)	Width (W)	Length (L)	Thickness (T)	A	Unit Weight
DR7X2M	557800	1.38"	0.3"	6.6'	0.04"	0.16"	1.46 lb
DR5-5X2M	557700	0.59"	0.22"	6.6'	0.04"	0.09"	0.73 lb
DR15X2M	557900	1.38"	0.6"	6.6'	0.06"	0.16"	2.87 lb

DIAGRAMS

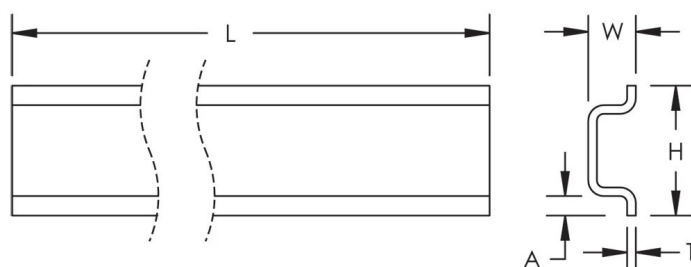

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE