


Click-In Profiles, CLPK

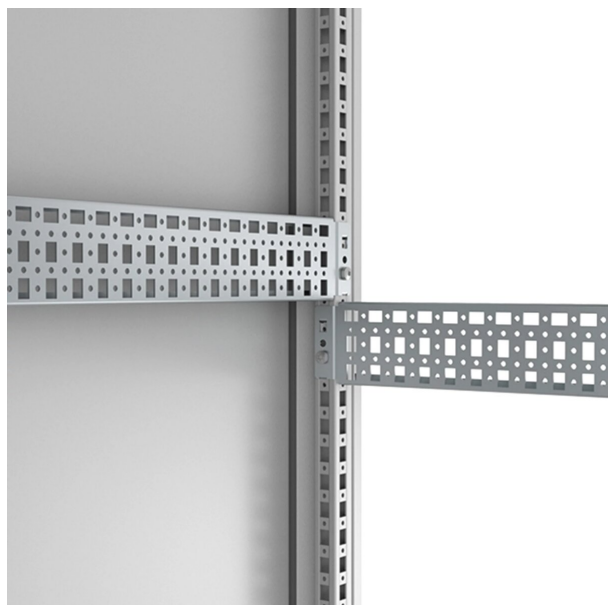

Additional accessories and electrical equipment can be mounted quickly and easily exactly where needed by using these click-in mounting profiles.

FEATURES

Description: Universal profile for both depth and width fitting on the 25 mm DIN hole pattern of the enclosure's frame or in combination with the CLPF and VB profiles. The 75 mm wide profile is equipped with three rows of holes of which one is turned 90°. This makes it possible to mount the CLPF profiles in both directions. The CLPK can be secured by the use of self tapping screws.

Material: 1.5 mm zinc plated steel.

Pack quantity: 4 profiles.

Thickness: 16ga
Material: Mild Steel
Finish: Zinc Plated

SPECIFICATIONS

Catalog Number	Article Number	Height	Width	Depth	Load Rating	Enclosure Material
CLPK500 	CLPK500	2.91in	19.69in	1.02in	2000N	Mild Steel
CLPK1000	CLPK1000	2.91in	39.37in	1.02in	1200N	Mild Steel
CLPK300		2.91in	11.81in	1.02in	2000N	Mild Steel
CLPK600 	CLPK600	2.91in	23.62in	1.02in	1600N	Mild Steel
CLPK800 	CLPK800	2.91in	31.5in	1.02in	1600N	Mild Steel
CLPK400	CLPK400	2.91in	15.75in	1.02in	1500N	Mild Steel
CLPK1200	CLPK1200	2.91in	47.24in	1.02in	1200N	Mild Steel

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE