


# Depth Dividing Bars For Floor Standing Enclosures, VBD

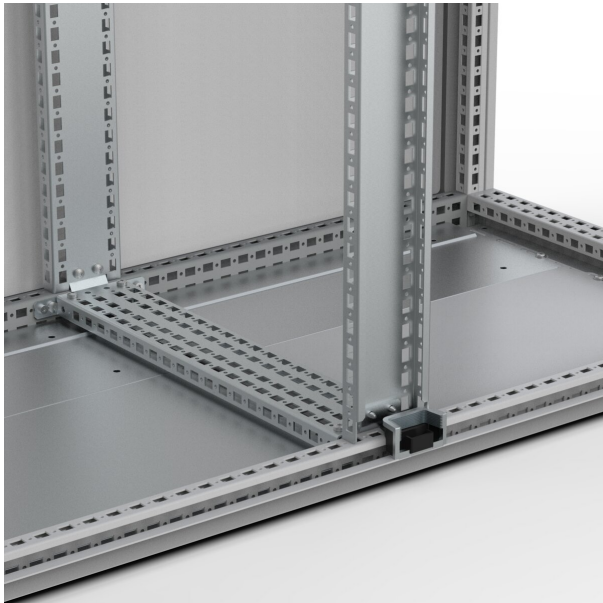

The dividing depth bar increases the mounting possibilities available within the enclosure and divides it into two useable spaces.

## FEATURES

**Description:** Fitted in the centre of a 1200 mm or 1600 mm wide enclosure (top and bottom), to provide standard mounting facilities in two sections of 600 mm or 800 mm wide. This enables separate fitting of accessories such as CAB(P), CBU, CLPK, CLPF etc., in either side of the enclosure. Accessories are adjustable in depth within the 25 mm hole pattern.

**Material:** 1.75 mm zinc plated steel.

**Pack quantity:** 1 pair without mounting accessories.

**Mounting requirements:** Add VBK for mounting. Add VB for complete mounting facilities in the division.

**Thickness:** 0.07in  
**Material:** Steel  
**Finish:** Zinc Plated

## SPECIFICATIONS

| Catalog Number | Height | Width   | Depth  | Enclosure Material |
|----------------|--------|---------|--------|--------------------|
| VBD400         | 0.94in | 15.75in | 3.54in | Mild Steel         |
| VBD600         | 0.94in | 23.62in | 3.54in | Mild Steel         |
| VBD800         | 0.94in | 31.5in  | 3.54in | Mild Steel         |
| VBD500         | 0.94in | 17.69in | 3.54in | Mild Steel         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**