

CIPP Tapered Plastic Push-In Plug for A12

FEATURES

Designed for use with the A12 coupler families

Designed to keep dirt and water out of the coupler during transportation and installation

Color coded for the appropriate coupler size




Material: Polyethylene

SPECIFICATIONS

Catalog Number	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color	Package Quantity
EL18CIPP			0.95"	0.28"	White	
EL10CIPP	#3		0.59"	0.28"	Yellow	1
EL16CIPP	#5	15M	0.84"	0.28"	Black	
EL14CIPP			0.76"	0.28"	Green	
EL12CIPP	#4	10M	0.67"	0.28"	Red	
EL20CIPP	#6	20M	1.06"	0.34"	Yellow	
EL22CIPP	#7		1.15"	0.34"	Blue	
EL25CIPP	#8	25M	1.27"	0.34"	Red	
EL28CIPP	#9	30M	1.39"	0.34"	Black	
EL30CIPP			1.48"	0.34"	White	
EL32CIPP	#10		1.56"	0.38"	Yellow	
EL40CIPP			1.89"	0.38"	Green	
EL34CIPP			1.65"	0.38"	Red	
EL36CIPP	#11	35M	1.73"	0.38"	Blue	

Catalog Number	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color	Package Quantity
EL38CIPP	#12		1.81"	0.38"	White	
EL57TCIPP	#18	55M	2.71"	0.44"	Blue	
EL50TCIPP			2.42"	0.44"	Black	
EL43TCIPP	#14	45M	2.13"	0.44"	Red	

DIAGRAMS

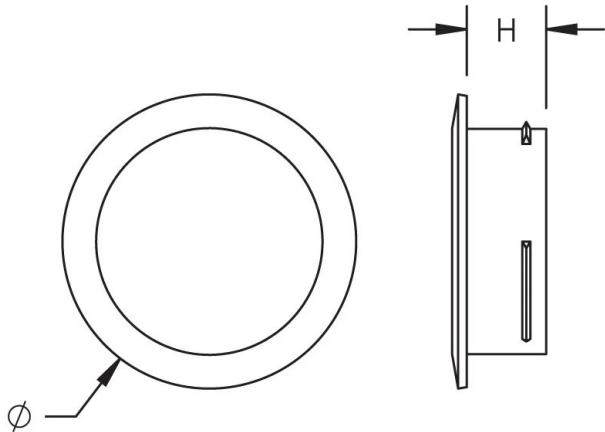

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE