

CPP Tapered Plastic Screw-In Plug for A12, A22 and A32K



FEATURES

Designed for use with the A12, A22 and A32K coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Color coded for the appropriate coupler size


Material: High Density Polyethylene (HDPE)

SPECIFICATIONS

Catalog Number	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color	Package Quantity
EL16CPPB100	#5	15M	0.87"	0.51"	Black	100
EL14CPPB100			0.87"	0.51"	Green	100
EL10CPPB100	#3		0.67"	0.51"	Yellow	100
EL18CPPB100			1.06"	0.51"	White	100
EL12CPPB100	#4	10M	0.67"	0.51"	Red	100
EL20CPPB100	#6	20M	1.06"	0.51"	Yellow	100
EL25CPPB100	#8	25M	1.3"	0.63"	Red	100
EL36CPPB50	#11	35M	1.81"	0.63"	Blue	50
EL32CPPB100	#10		1.65"	0.63"	Yellow	100
EL30CPPB100			1.46"	0.63"	White	100
EL40CPPB50			2.05"	0.63"	Green	50
EL28CPPB100	#9	30M	1.46"	0.63"	Black	100

Catalog Number	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color	Package Quantity
EL22CPPB100	#7		1.3"	0.63"	Blue	100
EL50CPPB40			2.52"	0.63"	Black	40

DIAGRAMS

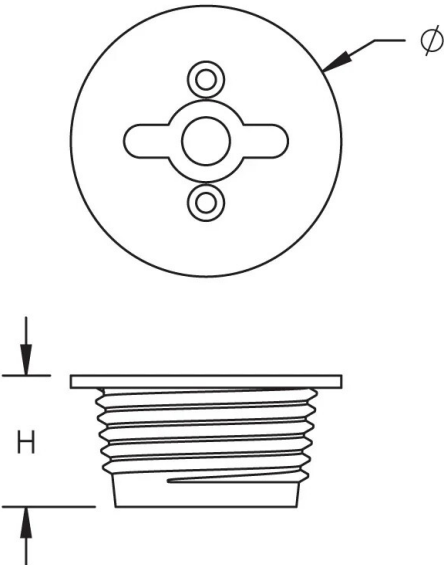

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE