

nVent LENTON Interlok Position Grout-Fill Coupler



FEATURES

Designed to splice the same diameter bars

Smaller bars can be installed into the over-sized cavity end if required

Positional feature allows the threaded coupler end to telescope out to close a gap between forms and to allow alignment of the grout tubes

Over-sized cavity allows for greater field tolerance

Taper-threaded end helps prevent movement of the reinforcing bars and eliminate misalignment

Requires less grout than most competitive systems

Material: Cast Iron

Finish: Plain

SPECIFICATIONS

Table 1/2

Catalog Number	Packaging	Rebar Size, US	Rebar Size, Canada	Diameter 1 (Ø1)	Diameter 2 (Ø2)	Length 1 (L1)
LK6STHD	Standard	#6	20M	2.56"	1.88"	10.44"
LK6STHDPKG	Bulk	#6	20M	2.56"	1.88"	10.44"

Catalog Number	Packaging	Rebar Size, US	Rebar Size, Canada	Diameter 1 (Ø1)	Diameter 2 (Ø2)	Length 1 (L1)
LK11STHD 	Standard	#11	35M	3.13"	2.44"	15.31"
LKT14STHD	Standard	#14	45M	3.7"	2.76"	19.09"

Table 2/2

Catalog Number	Length 2 (L2)	Length 3 (L3)	Bar Depth (BD)	Coupler Body (CB)	Unit Weight	Package Quantity
LK6STHD	11.19"	6.13"	1.09"	7.88"	5.4 lb	8
LK6STHDPKG	11.19"	6.13"	1.09"	7.88"	5.4 lb	
LK11STHD 	16.31"	9.88"	1.68"	12"	10.1 lb	4
LKT14STHD	19.88"	12.28"	2.2"	15.2"	18.26 lb	2


Designed to Meet: AASHTO;ABNT NBR 8548:1984;ACI 318 Type 1 (125% Specified Yield);ACI 318 Type 2 (Specified Tensile);ACI 349;ACI 359;AS3600

ADDITIONAL PRODUCT DETAILS

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

Prior to installation, please read and understand the detailed instructions and safety notices provided in the nVent LENTON Interlok Instruction Manual.

DIAGRAMS

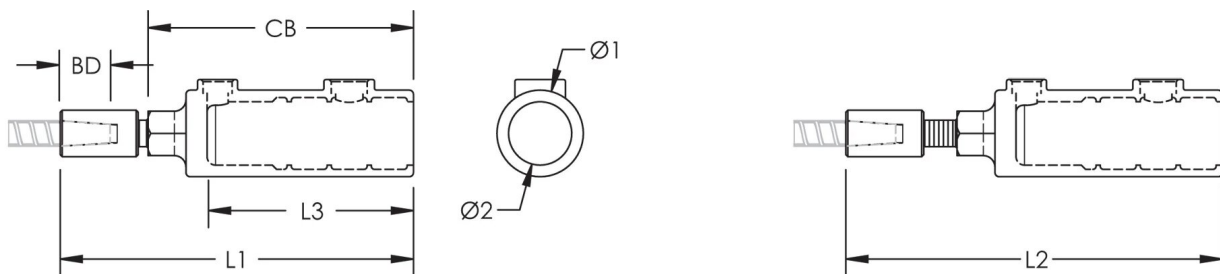

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE