


Countersunk Screw

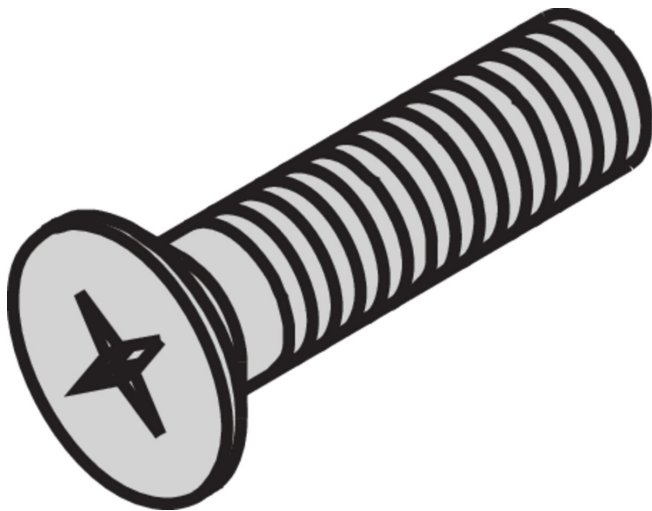

Flush surface, no interference with sliding parts. Self-centering in precision countersink. Clean external geometry (important for hygiene or airflow).

FEATURES

Countersunk screws are used for numerous mounting options in a subrack or desktop case.

Cross Recess imprint offers a high level of torque to achieve quick and easy installation

Torx imprint bears greater torque

The Torx star-shaped head prevents cam-out

Product Type: Screw



SPECIFICATIONS

Catalog Number	Material	Finish	Package Quantity	Thread Size	Type	Works With	Thread Type
24560-139	Steel	Zinc Plated	100	M4	Countersunk Screw	Front Panels	
24560-183	Steel	Zinc Plated	100	M5	Countersunk Screw	Front Panels	
24560-182	Steel	Zinc Plated	4	M5	Countersunk Screw	Front Panels	
24560-145	Steel	Zinc Plated	100	M4	Countersunk Screw	Front Panels	
24560-164	Steel	Nickel Plated	100	M2.5	Countersunk Screw	Front Panels	Metric
24560-158	Steel	Zinc Plated	100	M2.5	Countersunk Screw	Front Panels	
21100-542	Steel	Nickel Plated	100	M3	Screw	Front Panels	
21100-429	Steel	Nickel Plated	100	M2.5	Screw	Front Panels	

Catalog Number	Material	Finish	Package Quantity	ThreadSize	Type	Works With	ThreadType
21100-649	Steel	Zinc Plated	100	M2.5	Screw	Front Panels	
21100-500	Steel	Nickel Plated	100	M2.5	Screw	Front Panels	
21100-507	Steel	Nickel Plated	100	M2.5	Screw	Front Panels	

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE