


EuropacPRO 19" Subrack Kit for Backplane, Light, Unshielded

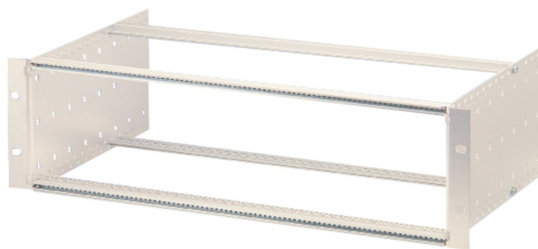

Non-EMC shielded subrack for backplane mounting, light version.

FEATURES

Subrack with side panel type L ("light") with integrated 19" support brackets

Horizontal rail type "light"

Aluminum construction

Rear horizontal rails for backplane mounting with insulation strip

Installed load up to 7.5 kg

Supplied as space-saving flat-pack

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Modifications such as cutouts, different finishes or dimensions available

Material:	Aluminum
Finish:	Anodized; Passivated
EMC Shielding:	No
Product Type:	Subrack/Chassis



SPECIFICATIONS

Table 1/2

Catalog Number	Rack Height	Package Quantity	Depth	For Mounting	Handle Included	Mounting
24564-131	3U	1	6.89in	Backplane	No	Rack
24564-132	3U	1	9.25in	Backplane	No	Rack
24564-433	6U	1	11.61in	Backplane	No	Rack
24564-133	3U	1	11.61in	Backplane	No	Rack
24564-432	6U	1	9.25in	Backplane	No	Rack
24564-431	6U	1	6.89in	Backplane	No	Rack

Table 2/2

Catalog Number	Complies With	Rack Width
24564-131	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP
24564-132	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP
24564-433	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP
24564-133	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP
24564-432	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP
24564-431	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP

ADDITIONAL PRODUCT DETAILS

Subrack is not prepared for shielding, retrofit for protection class IP 20 possible

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE