

EuropacPRO 19" Subrack Kit for Backplane, Shielded

EMC Shielded subrack for backplane mounting, rear side covered by a rear panel.



FEATURES

Subrack with side panel type F ("flexible"), front 19" bracket included, depth-adjustable 19" bracket sold separately (not included in items delivered)

Supplied as space-saving flat-pack

Modifications such as cutouts, different finishes or dimensions available

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

IP 20, in accordance with IEC 60529

Aluminum construction

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Rear horizontal rail for backplane mounting with insulation strip

Horizontal rail type "light"

Material:	Aluminum
Finish:	Anodized; Passivated
Product Type:	Subrack/Chassis
EMC Shielding:	Yes

SPECIFICATIONS

Table 1/2


Catalog Number	Rack Height	Package Quantity	Depth (D)	For Mounting	Gasket Type	Handle Included
24563-144	3U	1	13.98in	Backplane	Textile EMC	No
24563-145	3U	1	16.34in	Backplane	Textile EMC	No
24563-146	3U	1	18.7in	Backplane	Textile EMC	No
24563-143	3U	1	11.61in	Backplane	Textile EMC	No
24563-442	6U	1	9.25in	Backplane	Textile EMC	No
24563-443	6U	1	11.61in	Backplane	Textile EMC	No
24563-444	6U	1	13.98in	Backplane	Textile EMC	No
24563-445	6U	1	16.34in	Backplane	Textile EMC	No
24563-142	3U	1	9.25in	Backplane	Textile EMC	No
24563-446	6U	1	18.7in	Backplane	Textile EMC	No

Table 2/2

Catalog Number	Mounting	Complies With	Rack Width
24563-144	Rack	IEC 60297-3-103	84HP
24563-145	Rack	IEC 60297-3-103	84HP
24563-146	Rack	IEC 60297-3-103	84HP
24563-143	Rack	IEC 60297-3-103	84HP
24563-442	Rack	IEC 60297-3-103	84HP
24563-443	Rack	IEC 60297-3-103	84HP
24563-444	Rack	IEC 60297-3-103	84HP
24563-445	Rack	IEC 60297-3-103	84HP
24563-142	Rack	IEC 60297-3-103	84HP
24563-446	Rack	IEC 60297-3-103	84HP

ADDITIONAL PRODUCT DETAILS

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

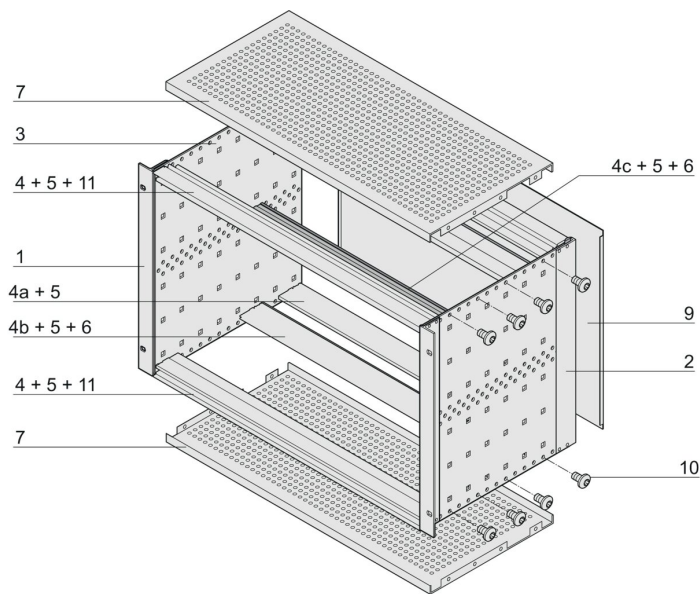

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE