

EuropacPRO Advanced EMC Side Panel Cover


Aluminium Side panel 3mm to increase the EMC shielding effect of the subrack by covering the not needed cut-outs.

FEATURES

Side panel covers for increased lateral RF shielding

Assembled on the outside of the standard side panel

Assembly material included

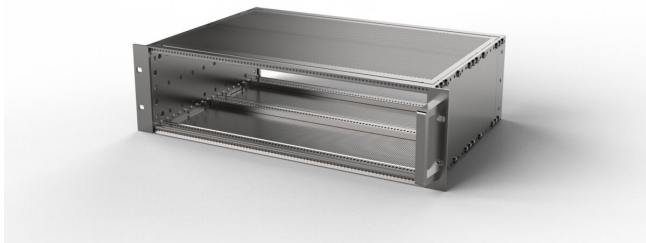

Material:	Aluminum
Product Family:	EuropacPRO
Finish:	Passivated
Product Type:	Side Panel
Works With:	Subracks
Type:	Type H
EMC Shielding:	Yes



SPECIFICATIONS

Table 1/2

Catalog Number	Rack Height	Package Quantity	Package Unit
24563-256	3U	2	Pair
24563-268	4U	2	Pair
24563-257	3U	2	Pair
24563-269	4U	2	Pair
24563-267	4U	2	Pair
24563-266	4U	2	Pair
24563-270	4U	2	Pair
24563-265	4U	2	Pair
24563-275	6U	2	Pair
24563-258	3U	2	Pair
24563-276	6U	2	Pair
24563-262	3U	2	Pair
24563-277	6U	2	Pair

Catalog Number	Rack Height	Package Quantity	Package Unit
24563-261	3U	2	Pair
24563-278	6U	2	Pair
24563-279	6U	2	Pair
24563-260	3U	2	Pair
24563-280	6U	2	Pair
24563-281	6U	2	Pair
24563-259	3U	2	Pair

Table 2/2

Catalog Number	Rack Height	Package Quantity	Package Unit
24563-282	6U	2	Pair
24563-255	3U	2	Pair

ADDITIONAL PRODUCT DETAILS

Side panel and 19" bracket are tox-cold welded together. token = Clinching technique, without add aids. This takes place with special tools and high pressure.

9 U version available on request.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE