


Mounting Plate for 19" Case and Subrack

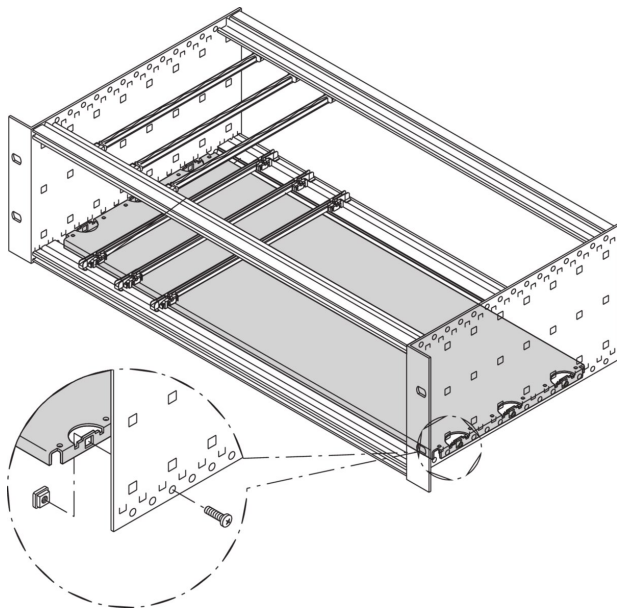

Mounting plate for heavy components or proprietary electronic assemblies. Suitable for RatiopacPRO/-AIR, CompacPRO and EuropacPRO.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

FEATURES

For assembly of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

Mounting plate, partial width: The partial width mounting plate fixed to the side panel by means of an assembly strip

The chassis plate can't be combined with EMC top- / bottom covers

Material: Aluminum
Product Type: Mounting Plate
Works With: Subracks



SPECIFICATIONS

Catalog Number	Rack Width	Package Quantity	Product Family	Certifications
34562-750	42HP	1	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	RoHS
34562-759	63HP	1	EuropacPRO, RatiopacPRO, CompacPRO	RoHS
34562-752	84HP	1	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	RoHS
34562-755	63HP	1	EuropacPRO, RatiopacPRO, CompacPRO	RoHS
34562-758	42HP	1	EuropacPRO, RatiopacPRO, CompacPRO	RoHS
34562-870	84HP	1	EuropacPRO	
34562-748	84HP	1	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	RoHS
34562-747	63HP	1	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	RoHS
34562-754	42HP	1	EuropacPRO, RatiopacPRO, CompacPRO	RoHS
34562-871	84HP	1	EuropacPRO	
34562-756	84HP	1	EuropacPRO, RatiopacPRO, CompacPRO	RoHS

Catalog Number	Rack Width	Package Quantity	Product Family	Certifications
34562-751	63HP	1	EuropacPRO, RatiopacPRO, CompacPRO, PropacPRO	RoHS
34562-760	84HP	1	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	RoHS
34562-746	42HP	1	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	RoHS
34562-745	28HP	1	EuropacPRO, RatiopacPRO, CompacPRO	RoHS
34562-753	28HP	1	EuropacPRO, RatiopacPRO, CompacPRO	RoHS
34562-757	28HP	1	EuropacPRO, RatiopacPRO, CompacPRO	RoHS
34562-749	28HP	1	EuropacPRO, RatiopacPRO, CompacPRO	RoHS

ADDITIONAL PRODUCT DETAILS

Please order assembly kit for mounting plate separately.

Other versions on request.

Fixing strips required for partial width, please order separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE