

Ground Rod Hex Driving Stud for Externally Threaded Ground Rods

FEATURES

Used in conjunction with threaded couplers while driving threaded ground rods




Material: Steel



SPECIFICATIONS

Catalog Number	Ground Rod Diameter, Nominal	Thread Size (TS)	Length (L)	Certifications
DS12	1/2"	1/2" UNC	38.1mm	
DS58	5/8"	5/8" UNC	44.5mm	RUS
DS34	3/4"	3/4" UNC	50.8mm	RUS

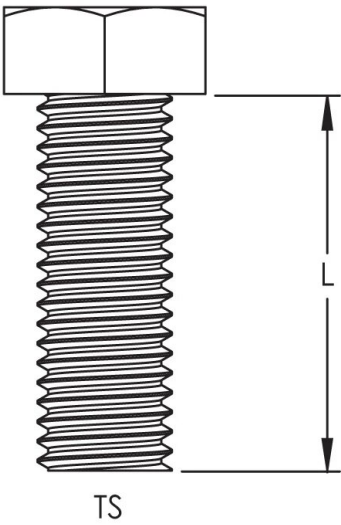

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE