


EuropacPRO Advanced EMC Cubierta de panel lateral, 4U, 295 mm

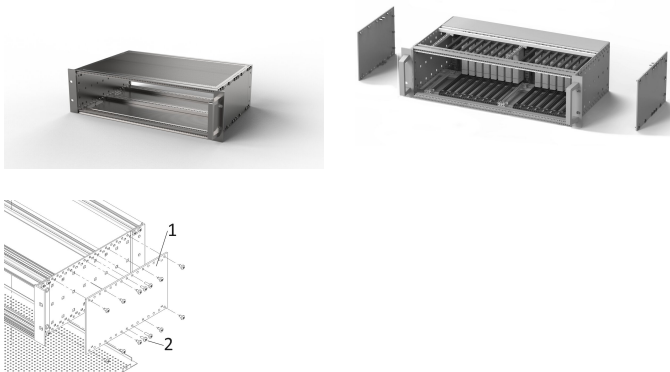

NÚMERO DE CATÁLOGO

24563-267

Panel lateral de aluminio de 3 mm para aumentar el efecto de blindaje EMC del subrack cubriendo los recortes no necesarios.

CARACTERÍSTICAS

Cubiertas laterales del panel para un mayor blindaje lateral del RF

Ensamblado en el exterior del panel lateral estándar

Material de montaje incluido



ATRIBUTOS DEL PRODUCTO

Altura del rack: 4U

Fondo: 295mm

Cantidad del paquete: 2

Apantallamiento EMC: Sí

Acabado: Pasivado

Longitud: 295mm

Material: Aluminio

Familia de productos: EuropacPRO

Tipo de producto: Panel lateral

Tipo: Tipo H

Compatible con: Subpistas

Unidad de paquete: Par

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products

may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

DETALLES ADICIONALES DEL PRODUCTO

El panel lateral y el soporte de 19" son soldados en frío tox. Toxen = técnica de clinching, sin ayudas añadidas. Esto se lleva a cabo con herramientas especiales y alta presión.

Versión 9 U disponible bajo petición.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Nuestra poderosa cartera de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE