


Sistema VXS, Torre, 5 U, 7 ranuras, PSU enchufable

Phase-out

NÚMERO DE CATÁLOGO

10836-060

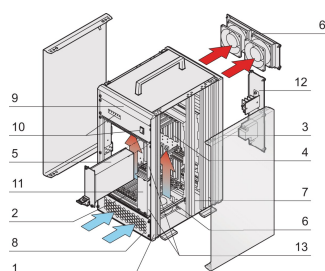

Sistema de torre VXS para 7 placas VXS 6 U, 160 mm. Con opción de E/S trasera la alimentación del sistema se suministra mediante una fuente de alimentación de marco abierto enchufable.

CARACTERÍSTICAS


Sistema conforme a IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; Backplane, conforme a VITA 41.0, -41.1, -41.10, ?41,11

PSU, 19" compatible, 300 W; opcionalmente se puede instalar una segunda PSU

Ranura para backplane VXS/VME64x4 VME64x, 6 U, con enchufe P0 3 x ranuras de carga útil VXS conectadas como anillo

Disipación de calor por 4 ventiladores, enfriamiento de la parte delantera a la trasera; temperatura controlada con módulo de control de ventilador (FCM)

Módulo de visualización para voltajes de funcionamiento DC, ventilador y alarma de temperatura

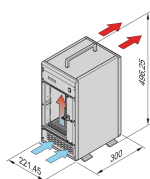

ATRIBUTOS DEL PRODUCTO

Tipo de producto: Sistema

Fondo: 300mm

Altura: 496.25mm

Anchura: 221.45mm

Potencia: 250W

Peso neto: 13.5kg



*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

DETALLES ADICIONALES DEL PRODUCTO

Sistemas modificados disponibles bajo petición.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Nuestro gran portafolio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE