


# PSU 19" para CompactPCI, DC/DC, 3 U, 8 HP

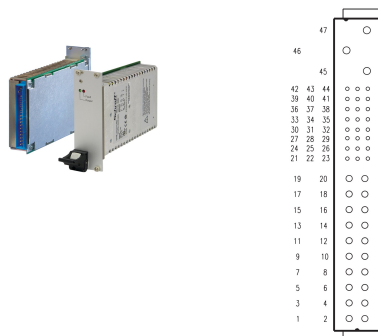

Obsoleto

## NÚMERO DE CATÁLOGO

**13100-142**

Fuente de alimentación enchufable de 19" con conector P47, para aplicaciones CompactPCI.

## CARACTERÍSTICAS

Conector P47 y señalización CompactPCI

4 voltajes de salida

Operación redundante con Bus Compartido actual (CSB), hot-swap



## ATRIBUTOS DEL PRODUCTO

Tipo de producto: Suministro de energía

Tipo: 19" DC/DC convertidor

Compatible con: CompactPCI y VME64x

Tensión de entrada de CC: 36 – 75V

Potencia: 250W

Número de tensiones de salida: 4

Tensión 1: 5V

Corriente 1: 40A

Tensión 2: 3.3V

Corriente 2: 40A

Tensión 3: 12V

Corriente 3: 5.5A

Tensión 4: -12V

Corriente 4: 2A

Altura del rack: 3U

Ancho del rack: 8HP

Fondo: 171.93mm

Peso neto: 0.94kg

Cantidad del paquete: 1

\*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

## ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Nuestra poderosa cartera de marcas:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**