

Carril Trasero Horizontal, Tipo AB para Guías de Tarjeta de E/S Trasera, 20 HP

NÚMERO DE CATÁLOGO

34561-520


Riel horizontal de extrusión de aluminio del tipo AB (AB = soporte), para guías de tarjetas E/S traseras, con superficie anodizada y superficie de contacto conductora. Adecuado para RatiopacPRO/-AIR y EuropacPRO/-robusto).

CARACTERÍSTICAS

Para CompactPCI en el área de la parte trasera I/O

Para una expansión de 2 x 3 U, se requieren 2 rieles horizontales de tipo AB

Extrusión de aluminio, superficie anodizada, superficie de contacto conductora, sin marcas HP

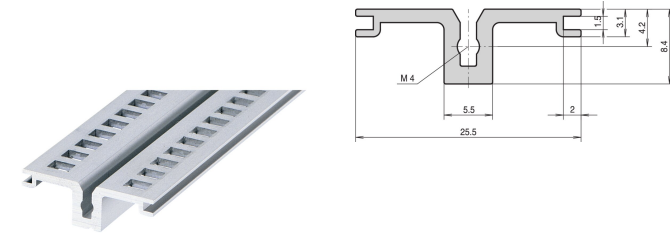

Combinations of horizontal rails and side panels

	Side panel not installed	Side panel installed	Side panel installed (not recommended)
Horizontal rail	+	+	+
Vertical rail	+	+	+
Horizontal rail	+	+	+
Vertical rail	+	+	+



ATRIBUTOS DEL PRODUCTO

Ancho del rack: 20HP

Cantidad del paquete: 1

Acabado: Anodizado

Longitud: 106.68mm

Material: Aluminio

Familia de productos: EuropacPRO; RatiopacPRO; RatiopacPRO AIRE; CompacPRO; PropacPRO

Tipo de producto: Carril horizontal

Tipo: Tipo AB

Compatible con: Subpistas; Casos

Peso bruto: 0.02kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products

may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

DETALLES ADICIONALES DEL PRODUCTO

La entrega es en paquete estándar múltiples. El precio es por artículo individual.

Tenga en cuenta que las entregas pueden realizarse en los SPQ indicados (SPQ, por ejemplo, 5 piezas, 10 piezas, 50 piezas, etc.). Diferentes cantidades de pedido (por ejemplo, 2 piezas) se pueden cambiar a la siguiente cantidad de entrega posible = Cantidad de paquete estándar.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Nuestra poderosa cartera de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE