

# Toetsen/codering voor IEL/IET-handgreep en IEEE Guide Rail

## CATALOGUSNUMMER

**20817-501**


Op basis van de IEEE-standaard geleiderails en -handgrepen kunnen worden gecodeerd om te voorkomen dat er een verkeerde kaart in de verkeerde sleuf wordt geplaatst.

## KENMERKEN

4 mogelijke posities, wat resulteert in 64 coderingen per kaartgeleider; bij het coderen van de bovenste en onderste kaartgeleider, zullen 4096 coderingen resulteren

Aangebracht in de kamers van de programmeerbare kaartgeleiders en in de achterzijde van het gegoten blok van de handgrepen type IEL of IET

Door de spie-/coderingspennen kunnen plug-in-units niet in verkeerde sleuven worden gemonteerd

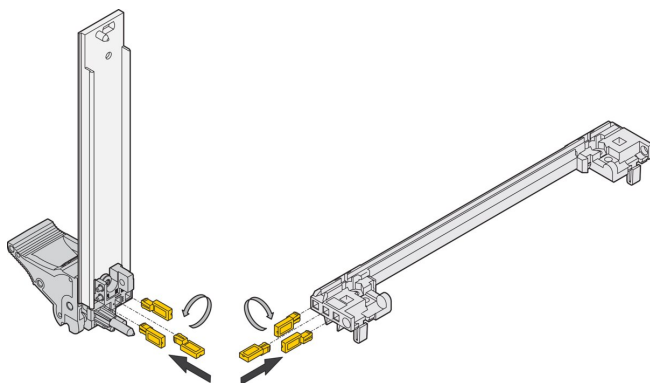

## PRODUCTKENMERKEN

Producttype: Indicator codering/sleutel

Productserie: EuropacPRO; RatiopacPRO; RatiopacPRO air; CompacPRO; PropacPRO; Inpac; Plug-in-eenheid frametype

Type: Coderingspin

Werkt met: Subracks; Omkastingen; Frontpanelen

Materiaal: Vezelversterkt kunststof

Ontvlambaarheidsklasse: UL® 94V-0

Hoeveelheid in verpakking: 100


Voldoet aan: EN 45545-2

Brutogewicht: 0.016kg

\*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address,

parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

## DIAGRAMMEN

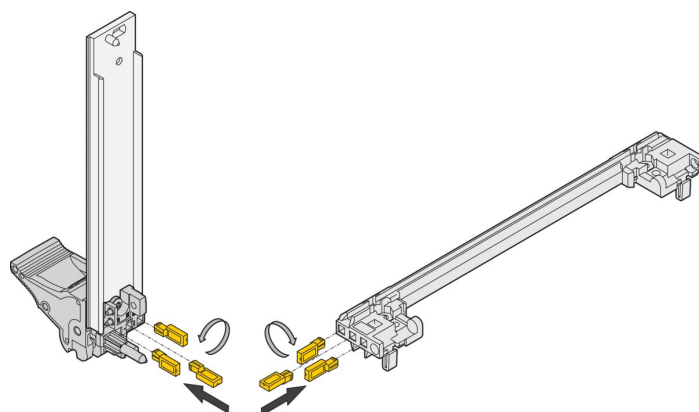

## WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op [www.nvent.com](http://www.nvent.com) en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Ons krachtige merkenportfolio:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**