


**Toevoerstation/uitneemgereedschap,  
handgreep type IEL, zwarte hendel, grijze knop,  
bovenkant, 100 stuks**

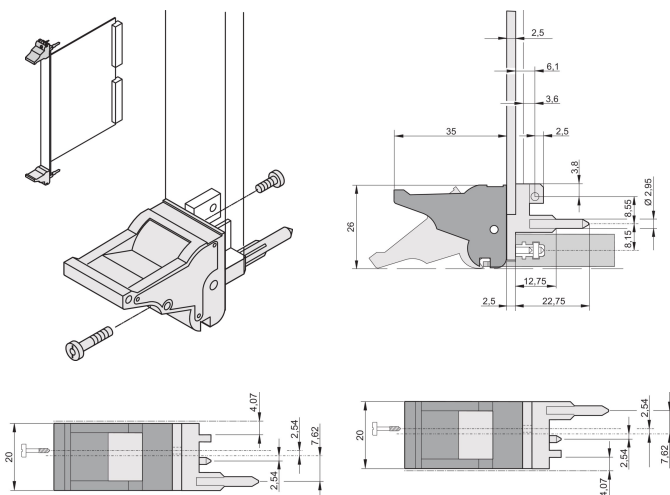

CATALOGUSNUMMER

**20817-615**

De handgreep van het  
toevoerstation/uitneemgereedschap, type IEL conform  
IEEE 1101.10. Twee van deze handgrepen kunnen een  
enkele hefboomkracht van 700 N (per paar) overwinnen.

## KENMERKEN

Geschikt voor insteek- en extractiekrachten tot 700 N (per paar)

In overeenstemming met IEEE 1101,10 en IEC 60297-3-102

Er kan een microschakelaar worden gemonteerd



## PRODUKTENMERKEN

Hoeveelheid in verpakking: 100

Type handgreep: IEL; Bovenkant voorkant; Onderste I/O achter

Ontvlambaarheidsklasse: UL® 94V-0

Kleur: Zwart

Voldoet aan: EN 45545-2

Materiaal: Polycarbonaat; Zinklegering

Producttype: Greep

Type: Inschuif-/uitschuifeenheid, standaard

Werkt met: Frontpanelen

Nettogewicht: 2.327kg


\*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address,

parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

## AANVULLENDE PRODUCTGEGEVENS

Bestel codeerpennen en microscharakelaar afzonderlijk.

## DIAGRAMMEN

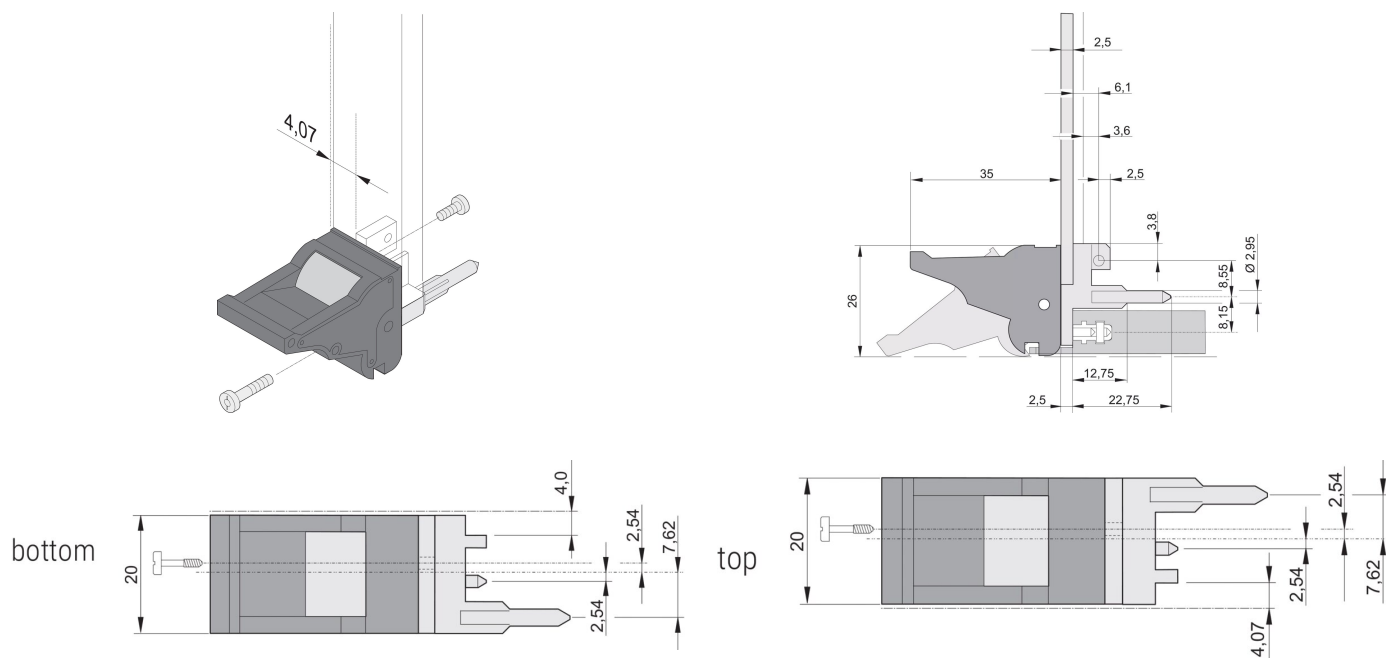

## WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op [www.nvent.com](http://www.nvent.com) en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

#### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

#### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

#### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

#### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Ons krachtige merkenportfolio:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**