

PMC Mezzanine voorpaneel, niet-afgeschermd, zwart gechromeerde zink die-gegoten

Phase-out

CATALOGUSNUMMER


20835-931

Het voorpaneel van de tussenverdieping is aangebracht in de uitsparingen van het PMC-voorpaneel. Beschikbaar in verschillende behandelingen.

KENMERKEN

Het voorpaneel van de tussenverdieping is aangebracht in de uitsparingen van het PMC-voorpaneel

EMC-afscherming met geleidende O-ring

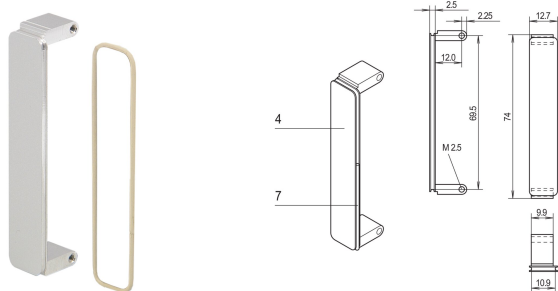

PRODUCTKENMERKEN

Producttype: Frontpaneel

Type: Frontpaneel zonder handgreep

Montage: Opschroefbare voorzijde

EMC-afscherming: Nee (achteraf te monteren)

Materiaal: Zink

Afwerking voorzijde: Geanodiseerd

Afwerking achterzijde: Geleidend

Behandelde randen: Nee

Hoogte: 74mm

Breedte: 12.7mm

Voldoet aan: PMC Mezzanine, IEEE P1386

Hoeveelheid in verpakking: 10

Nettogewicht: 0.23kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched

from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE