


Voorpaneelset, afgeschermd, onder scharnierend, 3 u, 84 pk, 2,5 mm, al, voor geanodiseerd, achter geleidend

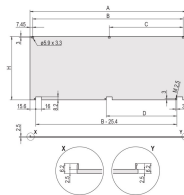

CATALOGUSNUMMER

20848-601

Onder scharnierend voorpaneel met u-profiel voor textielpakking.

KENMERKEN

Het voorpaneel met u-profiel kan worden losgedraaid bij een openingshoek van 135° (niet van RatiopacPRO)

Maakt montage op horizontale rails mogelijk

Afgeschermd, u-voorpaneel met EMC-pakking van textiel

Geschikt voor subracks (EuropacPRO) en tassen (RatiopacPRO, PropacPRO, CompacPRO)



PRODUCTKENMERKEN

Rekhoogte: 3U

Type accessoire: Frontpaneel

Rekbreedte: 84HP

Hoeveelheid in verpakking: 1

Montage: Scharnierend, onderkant

Type pakking: Textiel

Afwerking voorzijde: Geanodiseerd

Afwerking achterzijde: Geleidend

Behandelde randen: Nee

Voldoet aan: IEC 60297-3-101; IEEE 1101,1/10

Diepte (D): 2.5mm

EMC-afscherming: Nee (achteraf te monteren)

Afwerking: Geanodiseerd; Geëloxeerd

Hoogte (H): 128.4mm

Materiaal: Aluminium

Producttype: Frontpaneel

Type: Frontpaneel zonder handgreep

Breedte (W): 426.4mm


Brutogewicht: 0.546kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

AANVULLENDE PRODUCTGEGEVENS

Het voorpaneel kan in geopende stand worden verwijderd ($> 135^\circ$).

DIAGRAMMEN

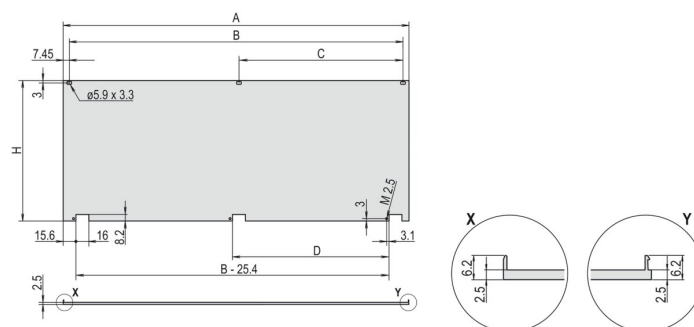

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE