


Geleiderail met codering IEEE ESD-klem, uitlijningspen

CATALOGUSNUMMER

24560-256

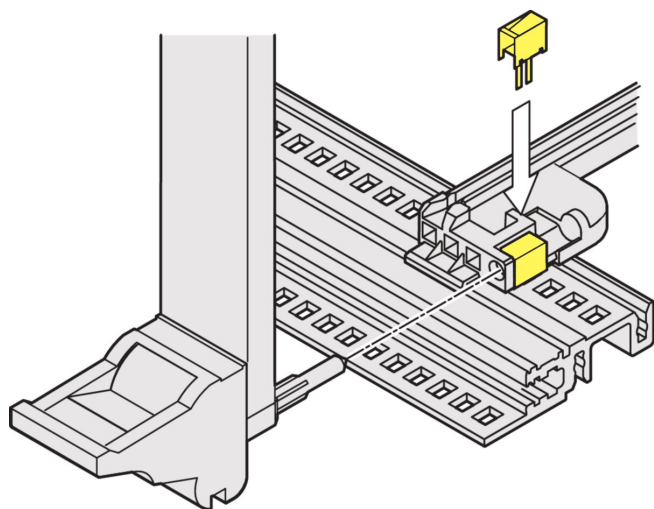

De ESD-klem kan met codering in het groef-/codeblok van de geleiderail worden gestoken. Zorgt voor geleidend contact tussen de uitlijningspen van de hendel van het toevoerstation/uitneemgereedschap (IEL of IET) en de horizontale rail.

KENMERKEN

Wordt gemonteerd in de onderste en bovenste horizontale rail

Voor de uitlijningspen volgens IEEE; kan worden aangesloten op de geleiderails met codering en in het groef-/codeblok; zorgt voor geleidend contact tussen de geleidepen van de handgreep van het toevoerstation/uitneemgereedschap (IEL of IET) en de horizontale rail



PRODUCTKENMERKEN

Producttype: Geleiderail

Productserie: EuropacPRO; RatiopacPRO; RatiopacPRO air; CompacPRO; PropacPRO; MultipacPRO; Inpac

Type: ESD-clip

Werkt met: Geleiderails; Omkastingen; Chassis

Materiaal: Staal

Hoeveelheid in verpakking: 50

Afwerking: Vertind

Brutogewicht: 0.024kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE