
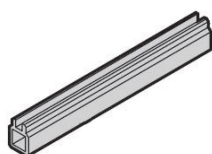
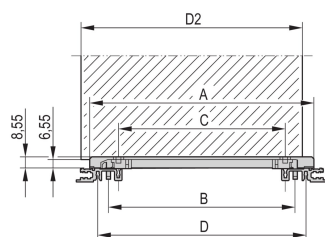


Geleiderail meerdelig, middenstuk, aluminiumextrusie, 340 mm, groefbreedte 2 mm, 10 stuks

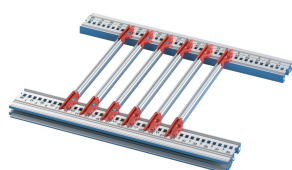

CATALOGUSNUMMER

34560-894

Middenstuk geleiderail voor afzonderlijke meerdelige geleiderails die niet uit kunststof of aluminium extrusie komen. Geschikt voor standaard, Accessory, 4,4-inch printplaten en eindstukken met codering.

KENMERKEN

Middenprofiel voor montage geleiderails voor een groefbreedte van 2 mm

er zijn 2 kunststof eindstukken nodig; deze worden aan beide uiteinden van het middenprofiel geduwd

Geleiderails kunnen worden vastgeklemd in horizontale rails (al-extrusie) of in platen van 1,5 mm dik

Opslagtemperatuur: Vanaf -40 °C ... 130 °C



PRODUCTKENMERKEN

Producttype: Geleiderail

Productserie: EuropacPRO; RatiopacPRO; RatiopacPRO air; CompacPRO; PropacPRO; MultipacPRO; Inpac

Type: Middelste gedeelte

Werkt met: Subracks; Omkastingen; Chassis

Diepte plaat: 340mm

Groefbreedte: 2

Materiaal: Aluminium

Kleur: Zilver

Hoeveelheid in verpakking: 1

Afwerking: Geanodiseerd

Nettogewicht: 0.017kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

AANVULLENDE PRODUCTGEGEVENS

Levering mav in Standard Pack Quantity (SPQ). De prijs is per afzonderlijk item.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE