


# Voorpaneel EMC roestvrijstalen beschermkit, 6 u; 10 stuks

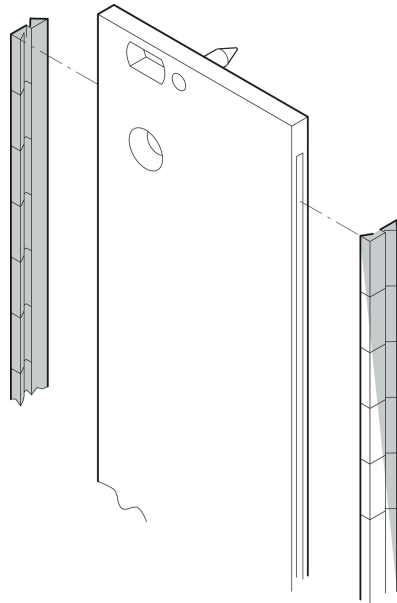

## CATALOGUSNUMMER

**21101-707**

De roestvrijstalen EMC-pakkingen worden in de zij sleuven van de afgeschermd voorpanelen geplaatst (2 stuks per voorpaneel).

## KENMERKEN

De roestvrijstalen EMC-pakkingen worden in de zij sleuven van de afgeschermd voorpanelen geplaatst (2 stuks per voorpaneel)

EMC-contactstrip, roestvrij staal

Temperatuurbereik -200 °C ... +160 °C



## PRODUCTKENMERKEN

Rekhoogte: 6U

Hoeveelheid in verpakking: 10

Diepte (D): 2.22mm

Materiaal: Roestvrij staal

Productserie: EuropacPRO; RatiopacPRO; RatiopacPRO air; PropacPRO; Plug-in-eenheid frametype

Producttype: Afschermingsset

Breedte (W): 4.97mm

Werkt met: Subracks; Omkastingen; Frontpanelen

Nettogewicht: 0.02kg

\*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.


## AANVULLENDE PRODUCTGEGEVENS

---

Bestel montagegereedschap afzonderlijk.

## DIAGRAMMEN

---

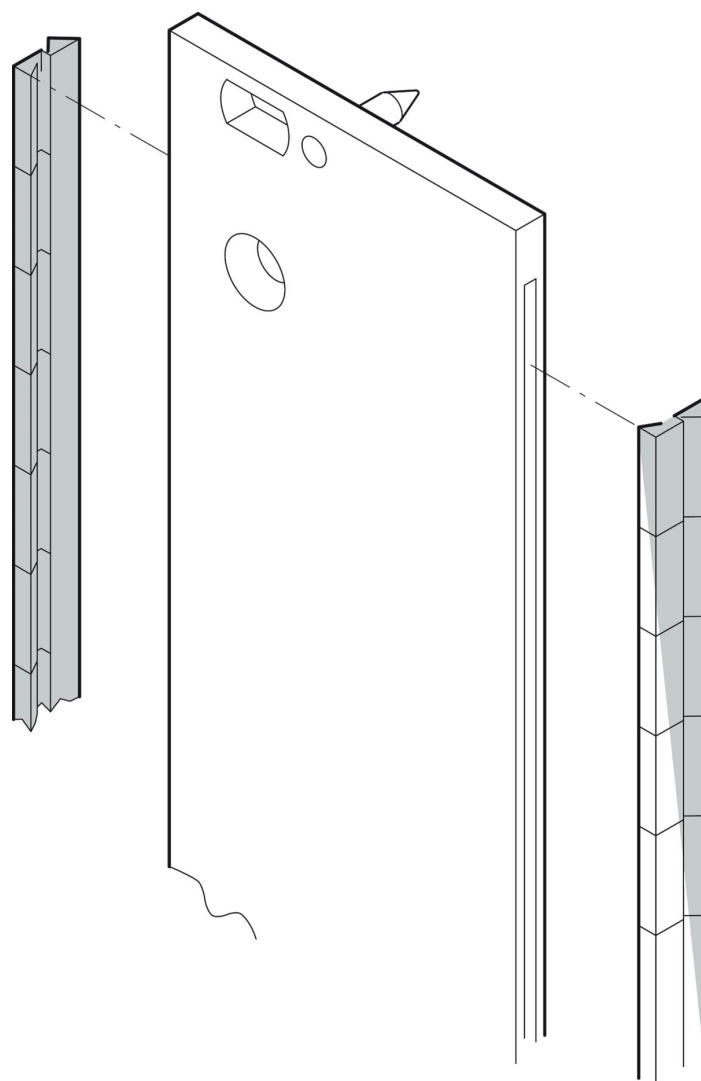

## WAARSCHUWING

---

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op [www.nvent.com](http://www.nvent.com) en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

#### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

#### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

#### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

#### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Ons krachtige merkenportfolio:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**