

Voorpaneel EMC roestvrijstalen beschermkit, voor u-vormige voorpanelen, 6 u, 100 stuks

CATALOGUSNUMMER

21102-108

De roestvrijstalen EMC-pakkingen worden in een sleuf aan de rechterkant van de u-vormige voorpanelen geplaatst.


De pakking wordt vastgeklemd op de steun van het rechtervoorpaneel, de 19-inch steun of het achterprofiel van de steun

KENMERKEN

De roestvrijstalen EMC-pakking voor SCHROFF u-vormige voorpanelen, biedt uitstekende prestaties op het gebied van de effectiviteit van de afscherming en een enorm temperatuurbereik van -200 tot +160°C.

Eenvoudige montage door de pakking vast te klemmen op de steun van het rechtervoorpaneel, de 19-inch steun of het achterprofiel van de steun

Temperatuurbereik van -200 tot 160 °C.

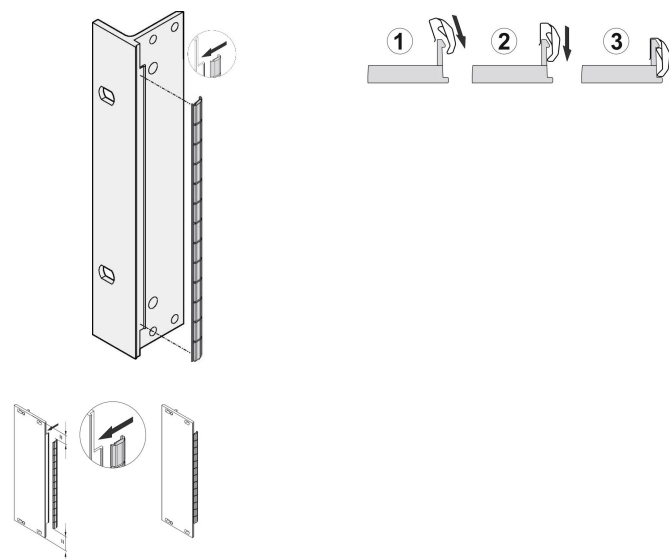

PRODUCTKENMERKEN

Rekhoogte: 6U

Hoeveelheid in verpakking: 100

Materiaal: Roestvrij staal

Productserie: EuropacPRO; RatiopacPRO; RatiopacPRO air; PropacPRO; Plug-in-eenheid frametype

Producttype: Afschermingsset

Rekbreedte: 100HP

Werkt met: Subracks; Omkastingen; Frontpanelen

Brutogewicht: 0.182kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

AANVULLENDE PRODUCTGEGEVENS

EMC-pakkingen (roestvrij) zijn vereist voor de afscherming van de voorpanelen.

DIAGRAMMEN



WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE