


Panhead schroef, Pozidrive

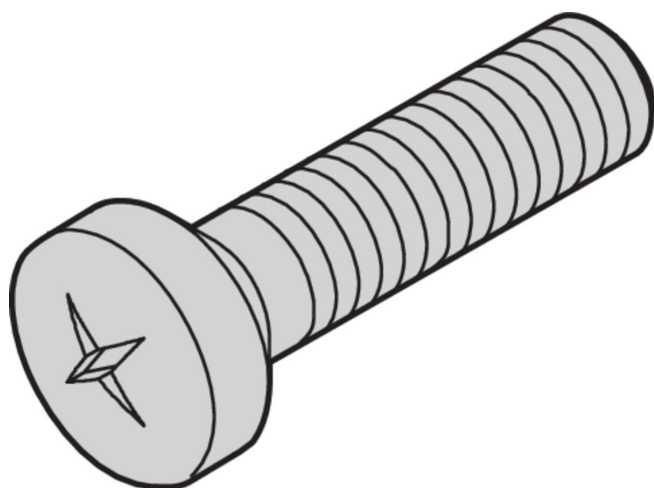

Panhead schroef, Pozidrive.

KENMERKEN

Panhead schroef, pozidrive

Producttype: Schroef
Materiaal: Staal



SPECIFICATIES

Table 1/2

Catalogusnummer	Diameter	Lengte	Afwerking	Hoeveelheid in verpakking	Schroefdraadmaat	Productserie
21102-024	3mm	6mm	Verzinkt	100	M3	
21120-150	5mm	10mm	Verzinkt	100	M5	
21101-314		5mm	Vernikkeld	100	M2.5	
21100-022	6mm	16mm	Verzinkt	100	M6	EuropacPRO, RatiopacPRO, RatiopacPRO air, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO
21120-203	6mm	16mm	Verzinkt	100	M6	
21100-021	6mm	16mm	Verzinkt	50	M6	EuropacPRO, RatiopacPRO, RatiopacPRO air, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO
21120-202	6mm	16mm	Verzinkt	50	M6	

Catalogusnummer	Diameter	Lengte	Afwerking	Hoeveelheid in verpakking	Schroefdraadmaat	Productserie
21100-650	6mm	16mm	Verzinkt	100	M6	EuropacPRO, RatiopacPRO, RatiopacPRO air, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO
21101-219		6mm	Vernikkeld	100	M2.5	Plug-in-eenheid frametype
21101-069		8mm	Vernikkeld	100	M2.5	Plug-in-eenheid frametype
21101-220		10mm	Vernikkeld	100	M2.5	Plug-in-eenheid frametype
21101-221		12mm	Vernikkeld	100	M2.5	Plug-in-eenheid frametype
21100-788		12mm	Verzinkt	100	M5	EuropacPRO
21101-222		16mm	Vernikkeld	100	M2.5	Plug-in-eenheid frametype

Table 2/2

Catalogusnummer	Type	Werkt met	Type schroefdraad	Certificeringen
21102-024	Panheadschoef		Metrisch	RoHS
21120-150	Coderingsblok	Behuizing		RoHS
21101-314	Panheadschoef	Achterplaten, Testadapters		RoHS
21100-022	Panheadschoef	Frontpanelen, Eurorack, Novastar, Varistar, Varistar CP		RoHS
21120-203	Panheadschoef	Frontpanelen, Eurorack, Novastar, Varistar, Varistar CP		
21100-021	Panheadschoef	Frontpanelen, Eurorack, Novastar, Varistar, Varistar CP		RoHS
21120-202	Panheadschoef	Frontpanelen, Eurorack, Novastar, Varistar, Varistar CP		
21100-650	Panheadschoef	Frontpanelen, Eurorack, Novastar, Varistar, Varistar CP		RoHS
21101-219	Panheadschoef	Achterplaten, Testadapters		RoHS
21101-069	Panheadschoef	Achterplaten, Testadapters		RoHS
21101-220	Panheadschoef	Achterplaten, Testadapters		RoHS
21101-221	Panheadschoef	Achterplaten, Testadapters		RoHS

Catalogusnummer	Type	Werkt met	Type schroefdraad	Certificeringen
21100-788	Panheadschroef	Subracks		RoHS
21101-222	Panheadschroef	Achterplaten, Testadapters		RoHS

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE