

Om bord rack 3 U, 84 HP

KATALOGNUMMER

10170-014

Egnet for pågående vibrasjoner, støt, høye temperaturer og høy luftfuktighet.

FUNKSJONER

For mobile jernbaneapplikasjoner

Egnet for pågående vibrasjoner, støt, høye temperaturer og høy luftfuktighet

Egnet for 1, 2 eller 3 U SNCF-subrakker (NF F61-005, CF 60-002)


Baksiden er utstyrt for standardkontakter. Tverrstag kan kodes for SNCF-kodepinnene

Tverrbjelke med integrert kabelkanal

Flere rack kan stables eller monteres i rader

Produsert ved hjelp av en sveiseprosess, sertifisert i henhold til en 15085 (CL2)

Rustfrie stålsveiser passivisert for å forhindre korrosjon

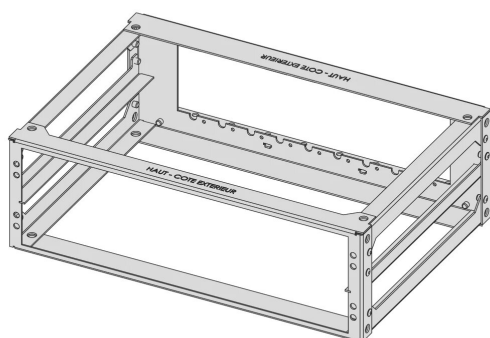

PRODUKTEGENSKAPER

Produktserie: Innebygd rack

Rackhøyde: 3U

Høyde: 156.7mm

Rackbredde: 84HP

Bredde: 496.4mm

Antall pakker: 1

Samsvarer med: SNCF NFF 61005; SNCF NFF 60002

Dybde: 341.8mm

Rammemateriale: Stål

Materiale: Rustfritt stål

Produkttype: Stativ

Statisk belastning: 25kg

Bruttovekt: 4.35kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE