

VXS-system, tårn, 5 U, 7 spor, Pluggable PSU

Phase-out

KATALOGNUMMER

10836-060

VXS tårnsystem for 7 VXS-plater 6 U, 160 mm. med bakre i/O-alternativ får systemet strøm fra en pluggbar åpen rammestrømforsyning.

FUNKSJONER




System i samsvar med IEC 60297-3-101, '102, '103; IEEE 1101,1 , 1101,10/11; bakplan, samsvarer med VITA 41,0, '41,1, '41,10, '41,11

Strømforsyningsenhet, kompatibel med 19 tommer, 300 W; en ekstra strømforsyningsenhet kan monteres som tillegg utstyr

Bakplan VXS/VME64x4 -spor VME64x, 6 U, med P0-plug3 x VXS-nyttelastspor koblet til som ring

Varmespredning av 4 vifter, kjøling fra front til bak; temperaturkontrollert med viftestyremodul (FCM)

Skjermmodul for DC-driftsspenninger, vifte og temperaturalarm

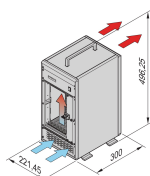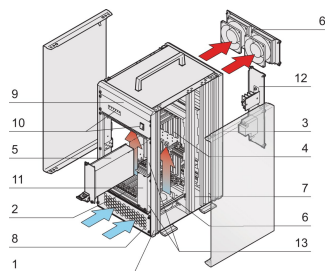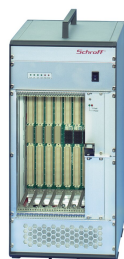

PRODUKTEGENSKAPER

Produkttype: System

Dybde: 300mm

Høyde: 496.25mm

Bredde: 221.45mm

Effekt: 250W

Nettovekt: 13.5kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Modifiserte systemer tilgjengelig på forespørsel.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE