


Innsetter / Extractor håndtak type IET, svart spak, grå knapp, bunn; 10 stykker

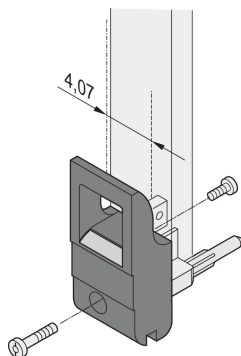

KATALOGNUMMER

20817-652


Innsettingshåndtaket/avtrekkshåndtaket av type IET i henhold til IEEE 1101,10. To av disse håndtakene kan overvinne en enkelt håndtakskraft på 700 N (per par).

FUNKSJONER

Egnet for innsetting og ekstraksjonskrefter opp til 700 N (per par)

I henhold til IEEE 1101,10 og IEC 60297-3-102

En mikrobryter kan monteres

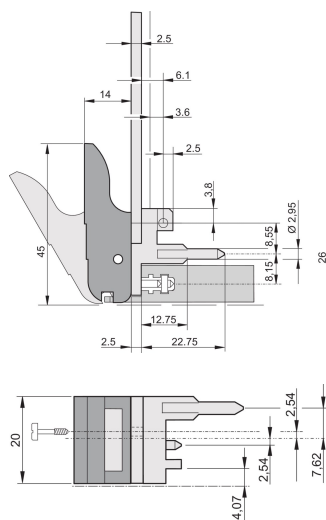

PRODUKTEGENSKAPER

Antall pakker: 10

Håndtakstype: IET; Nederst foran; Øvre bakre i/O

Antennbarhetsvurdering: UL® 94V-0

Farge: Kullsvart

Fargekode: RAL 9005

Samsvarer med: EN 45545-2

Dybde (D): 39.15mm

Høyde (H): 44.65mm

Materiale: Polykarbonat; Sinklegering

Produkttype: Håndtak

Type: Innsetter/uttrekker, standard

Bredde (W): 19.8mm

Fungerer med: Frontpaneler


Nettovekt: 0.233kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Vennligst bestill kodepinner og mikrobryter separat.

DIAGRAMMER

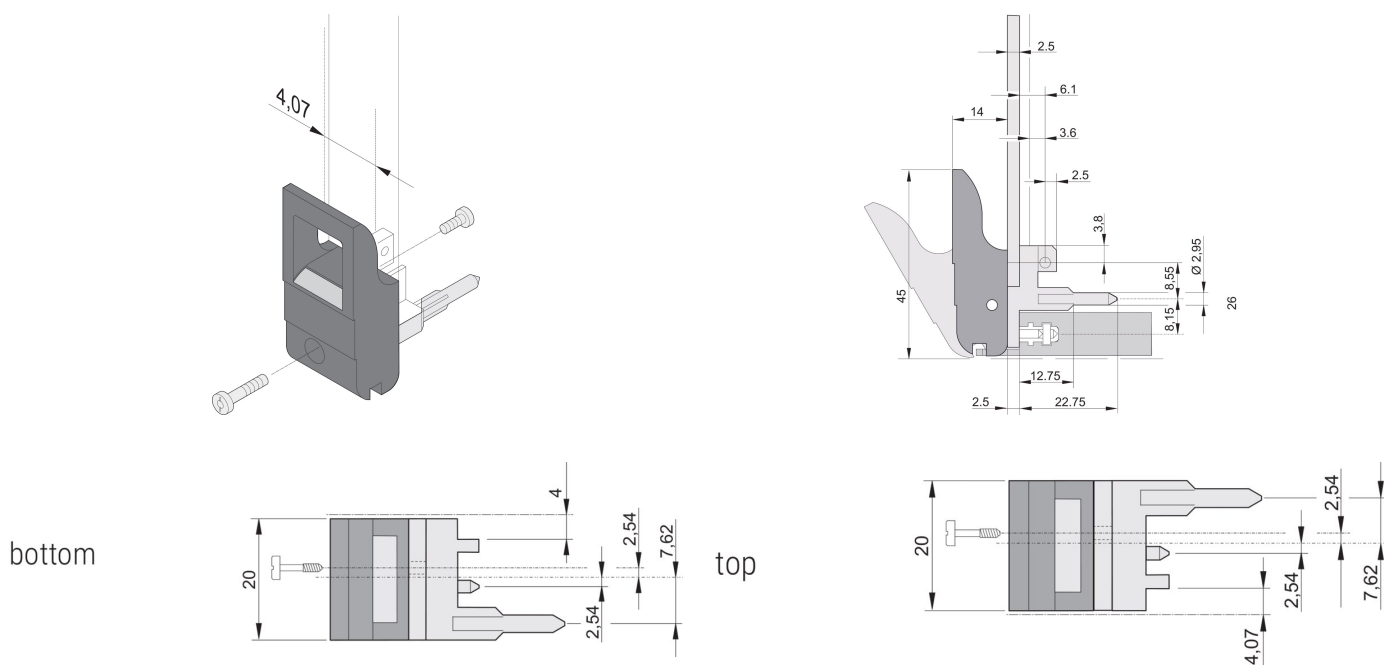

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE