


Innsetter/extractor håndtak type IEL, svart spak, grå knapp, topp, 100 stykker

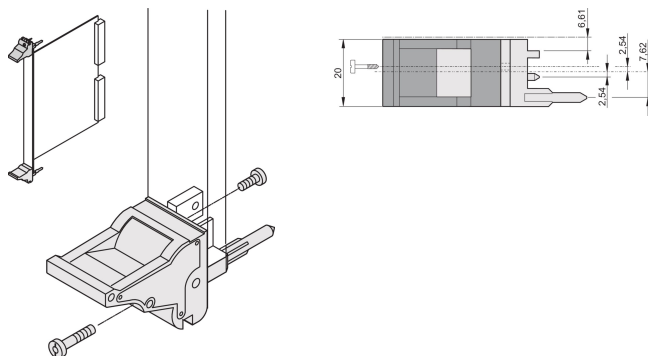

KATALOGNUMMER

20817-685

Innsetter/avtrekkshåndtak av type IEL i henhold til IEEE 1101,10. 0,1-tommers forskyvning to av disse håndtakene kan overvinne en enkelt håndtakskraft på 700N (per par).

FUNKSJONER

Egnet for innsetting og ekstraksjonskrefter opp til 700 N
(per par)

I henhold til IEEE 1101,10 og IEC 60297-3-102

En mikrobryter kan monteres

0,1-tommers offset brukes for PSU med SMD Plus



PRODUKTEGENSKAPER

Antall pakker: 100

Håndtakstype: IEL; Øverst foran

Antennbarhetsvurdering: UL® 94V-0

Farge: Svart

Samsvarer med: EN 45545-2

Materiale: Polykarbonat; Sinklegering

Produkttype: Håndtak

Type: Innsetter/uttrekker, 0,1-tommers forskyvning

Fungerer med: Frontpaneler


Bruttovikt: 2.384kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Vennligst bestill kodepinner og mikrobryter separat.

DIAGRAMMER

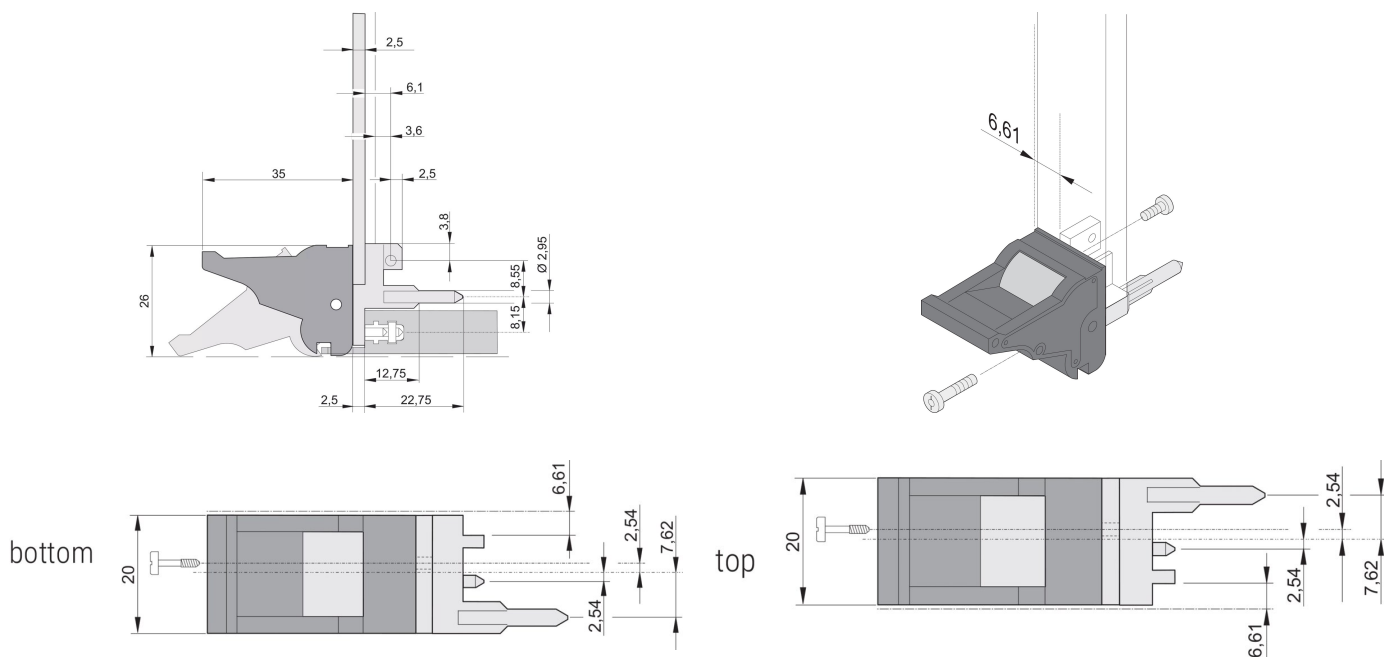

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmaterieill. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE