


# Innsetter / Extractor håndtak type IET, grå spak, svart knapp, topp, 100 stykker

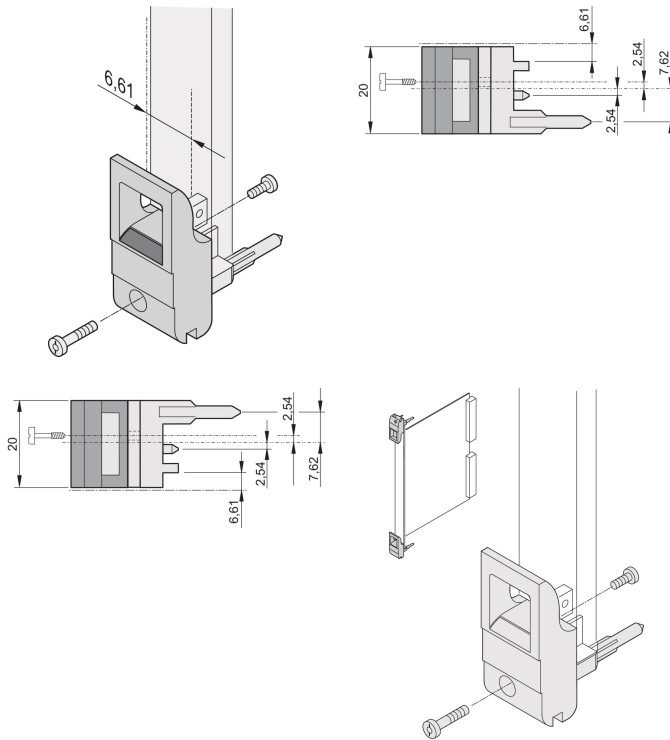

## KATALOGNUMMER

**20817-717**

Innsetningshåndtaket/avtrekkshåndtaket av type IET i henhold til IEEE 1101,10. 0,1-tommers forskyvning. To av disse håndtakene kan overvinne en enkelt håndtakskraft på 700 N (per par).

## FUNKSJONER

Egnet for innsetting og ekstraksjonskrefter opp til 700 N (per par)

I henhold til IEEE 1101,10 og IEC 60297-3-102

En mikrobryter kan monteres

0,1-tommers offset brukes for PSU med SMD Plus



## PRODUKTEGENSKAPER

Antall pakker: 100

Håndtakstype: IET; Øverst foran

Antennbarhetsvurdering: UL® 94V-0

Farge: Grå

Materiale: Polykarbonat

Produkttype: Håndtak

Type: Innsetter/uttrekker, 0,1-tommers forskyvning

Fungerer med: Frontpaneler

Nettvekt: 2.28kg


\*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched

from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

## YTTERLIGERE PRODUKTDETALJER

Vennligst bestill kodepinner og mikrobryter separat.

## DIAGRAMMER

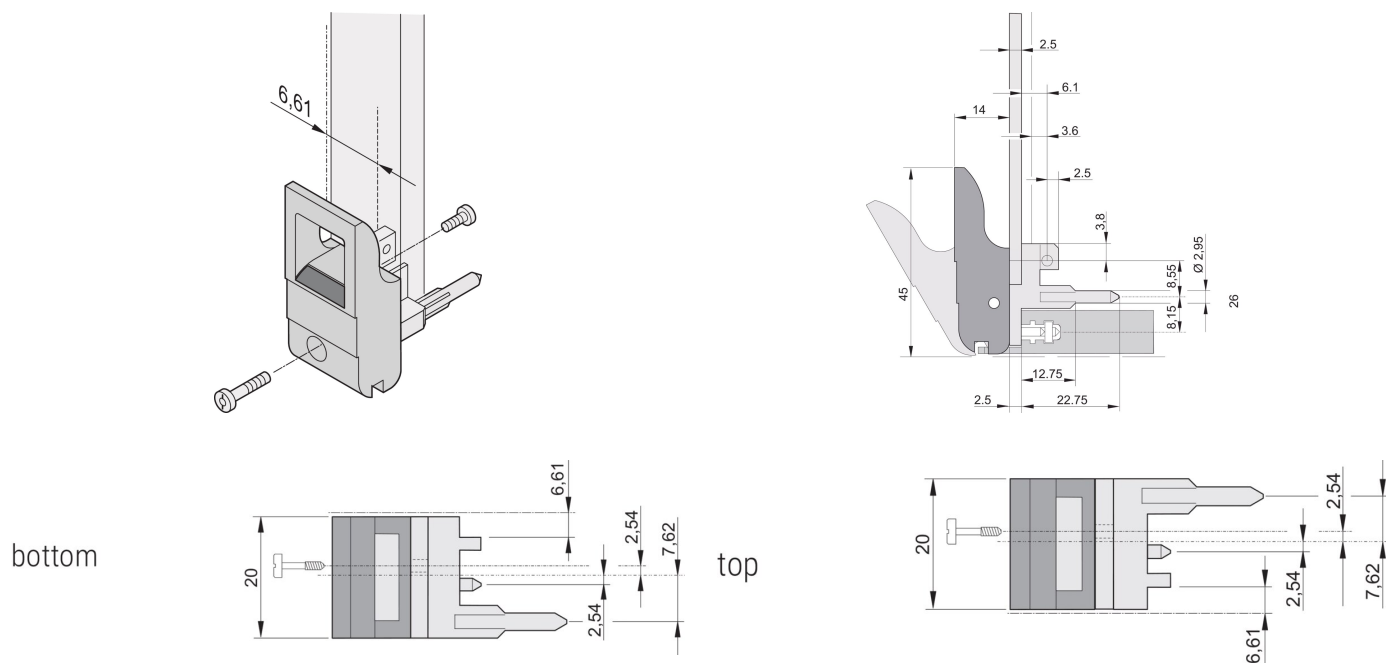

## ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på [www.nvent.com](http://www.nvent.com) og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

#### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Vår solide portefølje av merkevarer:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**