


Plug-in Unit Kit for PMC med IEL håndtak svart, U-formet frontpanel skjermet (tekstil), 3 U, 4 HP

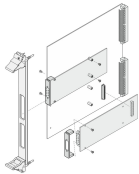

KATALOGNUMMER

20836-460

U-formet frontpanel med utskjæring for PMC. Kan reguleres for tekstil EMC-pakning.

FUNKSJONER

I henhold til IEEE P1386, PCI Mezzanine Card

For enkle 69,0 x 76,5 mm eller doble 139,0 x 76,5 mm moduler

For standard definerte i/O mezzanine moduler som kobles til bærekort

PMC = PCI Mezzanine-kort

FPGA = feltprogrammerbar Gate-matrise

U-profil frontpanel 3 U, 4 hk, med tekstile pakninger

EMC-skjerming for frontpanel og belegg for utskjæringer i frontpanel

PRODUKTEGENSKAPER

Rackhøyde: 3U

Antall pakker: 1

Håndtakstype: IEL

Montering: Front som skrues på

Pakning: Tekstil

Fremre overflate: Anodisert

Bakre flate: Strømledende

Samsvarer med: PMC Mezzanine, IEEE P1386

EMC-beskyttelse: Ja

Overflate: Anodisert, Passivert

Materiale: Aluminium

Produkttype: Frontpanel

Rackbredde: 4HP

Type: Frontpanel med håndtak (PIU)

Nettovekt: 0.088kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE