


Frontpanel, U-profil, frostbeskyttelse, 3 U, 84 HP, 2,5 mm, Al, fremre anodisert, bakre ledende

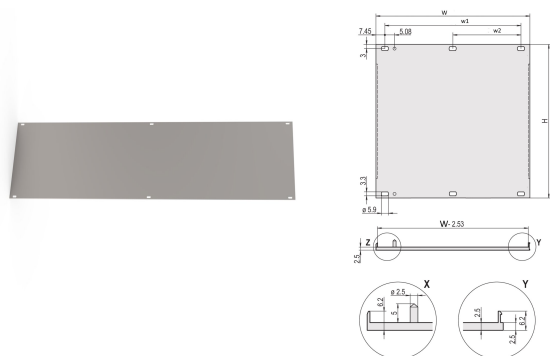

KATALOGNUMMER

20848-097

U-profil frontpanel for tekstil EMC-pakning.

FUNKSJONER

U-profil, frontpanel, Al, 2,5 mm, front anodisert, bakre ledende

For EMC-tekstilpakning



PRODUKTEGENSKAPER

Rackhøyde: 3U

Rackbredde: 84HP

Antall pakker: 1

Tilbehørstype: Frontpanel

Montering: Front som skrus på

Pakning: Tekstil

Fremre overflate: Anodisert

Bakre flate: Strømlerende

Behandlede kanter: Nei

Samsvarer med: IEC 60297-3-101; IEEE 1101,1/10

Dybde (D): 2.5mm

EMC-beskyttelse: Nei (kan monteres etterpå)

Overflate: Anodisert; Passivert

Høyde (H): 128.4mm

Materiale: Aluminium

Produkttype: Frontpanel

Type: Frontpanel uten håndtak

Bredde (W): 426.4mm

Nettovekt: 0.397kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Vennligst bestill festemateriale (hylser, krageskruer) separat.

14 ... 84 HP: Flerdelt U-profil (frontpanel med krympede profiler).


Forskjeller i finish mellom 2... 12 HP og 14 ... 84 HK.

2 ... 12 HP: U-profil i én del

Bestill EMC-pakningen for tekstil separat.

Standard pakkeantall: 2 til 28 hk: 5 stykker, 42 til 84 hk: 1 stk. leveres kun i standard pakningsstørrelser (SPQ).

DIAGRAMMER

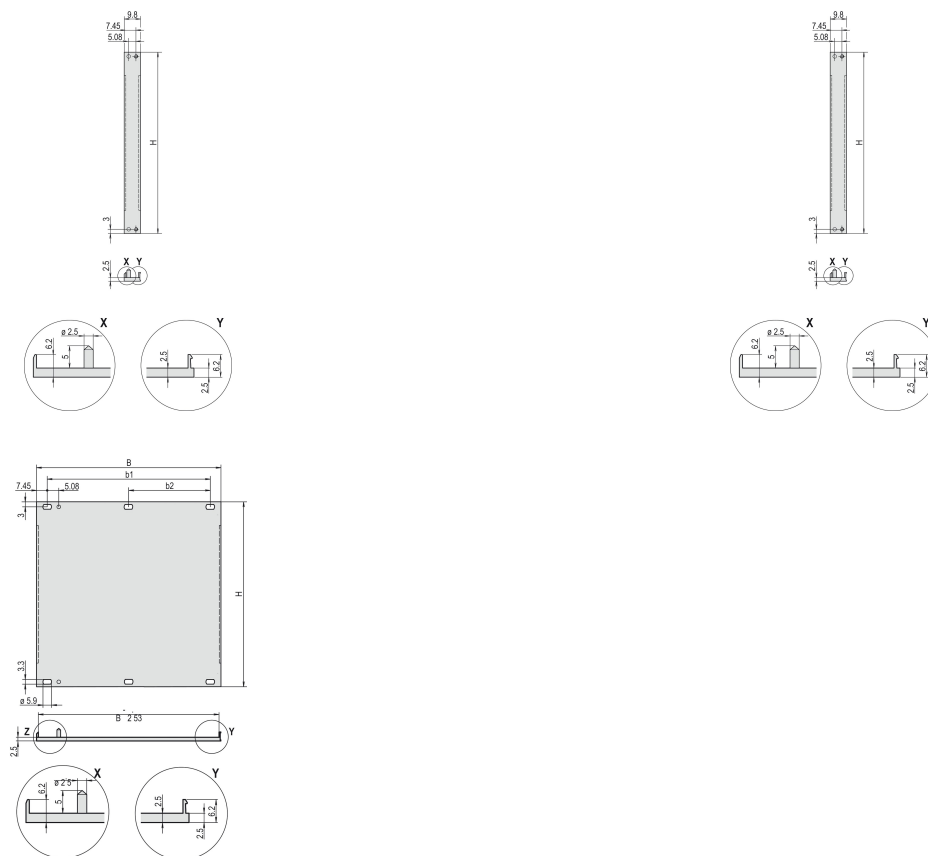

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmaterieil. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE