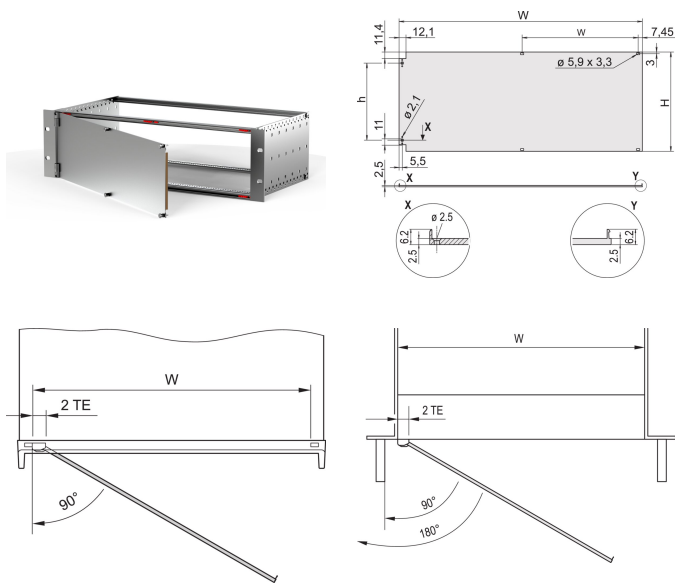


**Frontpanel, skjermet, sidehengslet, 3 U, 84 hk,
2,5 mm, Al, fremre anodisert, ledende bak**



KATALOGNUMMER

20848-611

Frontpanel med tekstil EMC-pakning, sidehengslet
montering.

FUNKSJONER

Frontpanel med tekstil EMC-pakning

Muliggjør montering på de horisontale skinnene

Egnet for subracks og tilfeller

Hengslene kan monteres på venstre eller høyre side



PRODUKTEGENSKAPER

Rackhøyde: 3U

Antall pakker: 1

Tilbehørstype: Frontpanel

Montering: Hengslet, side

Pakning: Tekstil

Fremre overflate: Anodisert

Bakre flate: Strømledende

Behandlede kanter: Nei

Dybde (D): 2.5mm

EMC-beskyttelse: Nei (kan monteres etterpå)

Overflate: Anodisert; Passivert

Høyde (H): 128.4mm

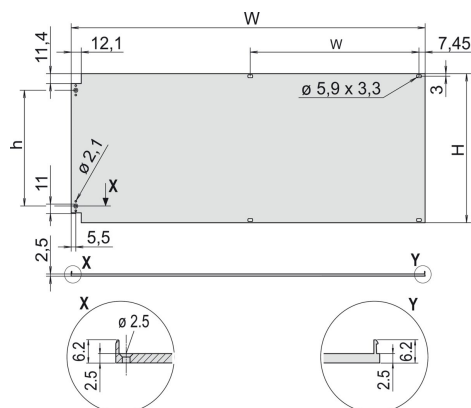
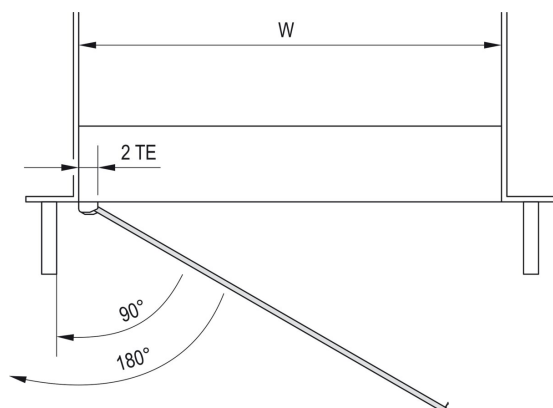
Materiale: Aluminium

Produkttype: Frontpanel

Type: Frontpanel uten håndtak

Nettovekt: 0.56kg

DIAGRAMMER

**ADVARSEL**

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nyvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE