 



Frontpanel EMC rustfritt stål skjermsett, for U-formede frontpaneler, 3 U, 100 stykker

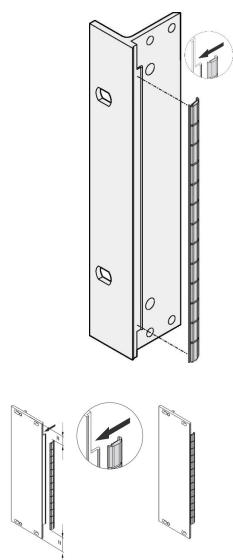

KATALOGNUMMER

21102-106

De rustfrie EMC-pakningene settes inn i et spor på høyre side av de U-formede frontpanelene.

Pakningen klippes på høyre frontpanel brakett, 19-tommers brakett eller bakre profil av slikken

FUNKSJONER

EMC-pakningen i rustfritt stål for SCHROFF U-formede frontpaneler, gir utmerket ytelse i skjermingseffektivitet og et enormt temperaturområde fra -200 til +160°C.

Enkel montering ved å feste pakningen på braketten på høyre frontpanel, 19-tommers brakett eller bakre profil på underplaten

Temperaturområde fra -200 til +160°C.

PRODUKTEGENSKAPER

Rackhøyde: 3U

Antall pakker: 100

Materiale: Rustfritt stål

Produktserie: EuropacPRO; RatiopacPRO; RatiopacPRO Air; PropacPRO; Rammetype, pluggbar enhet

Produkttype: Skjermingssett

Rackbredde: 100HP


Fungerer med: Delrack; Esker; Frontpaneler

Bruttovekt: 0.072kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

EMC-pakninger (rustfritt) kreves for skjerming av frontpanelene.

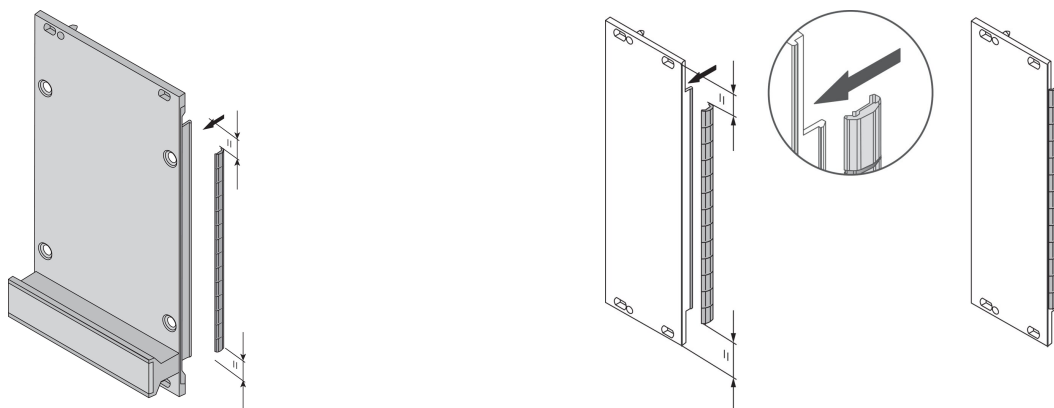

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE