

Teleskopiske lysbilder C-profil for kabinett for montering av LABRACK, 250 mm

KATALOGNUMMER

24562-446



Teleskopiske rutsjebaner med styreprofil for montering i skap med 25 kg lastekapasitet.

FUNKSJONER

For montering av 84 hk brede subracks i 19-tommers planet

Lastekapasitet: 25 kg per par.

Styringsprofilen (1) er tilpasset festedimensjonen i skapet (den er boltet til skapsprofilen på 19 tommer); adapterskinne (3) er tilpasset dybde- og festedimensjonen på underholderen (den settes inn i styringsprofilen som en teleskopisk skyvebryter)

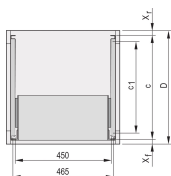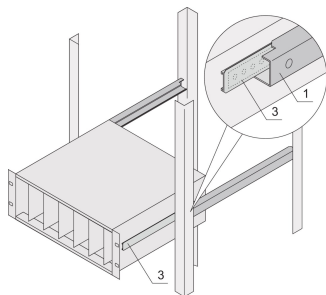

PRODUKTEGENSKAPER

Produktserie: Labrack

Dybde: 250mm

Antall pakker: 2

Overflate: Anodisert

Materiale: Aluminium

Produkttype: Uttrekkbar skinne

Type: C-profil

Bruttovekt: 0.304kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Ingen beskyttelse mot ekstraksjon, ingen stopp ved full forlengelse.

Armeringsjernbanen og C-Rails er testet i henhold til den russiske atomenergimyndigheten GAN standarder.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell.

Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE